


# STANDARD DIMENSION ADAPTORS AND REDUCING BUSHINGS

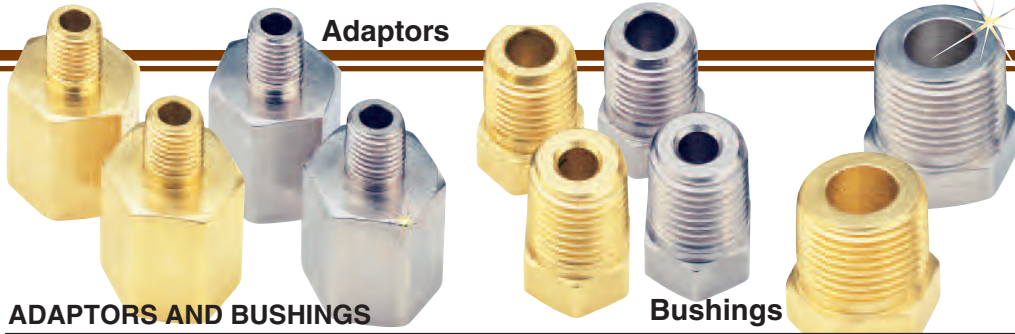

Adaptors

Bushings

- ✓ Rugged Design
- ✓ Available in Stainless Steel, Brass, or Carbon Steel
- ✓ Reduce Down to 1/8 NPT
- ✓ Adapt Up to 1 NPT


**MOST POPULAR  
MODELS HIGHLIGHTED!**

ADAPTORS AND BUSHINGS

## To Order (Specify Model Number)

NPT THREAD		ACROSS HEX FLATS INCHES	LENGTH INCHES	BRASS		STAINLESS STEEL	
MALE	FEMALE			MODEL NO.	MODEL NO.		
<b>REDUCING ADAPTORS</b>							
1/8	1/4	1 1/8	1.50	RA-18-14-BR	RA-18-14-SS		
1/8	1/2	1 1/8	1.50	RA-18-12-BR	RA-18-12-SS		
1/4	1/2	1 1/8	1.69	RA-14-12-BR	RA-14-12-SS		
1/2	3/4	1 3/8	1.94	RA-12-34-BR	RA-12-34-SS		
1/2	1	1 5/8	2.16	—	RA-12-1-SS		
7/16-20	1/4	9/16	1.25	—	RA-716-14M-SS		
7/16-20	1/4 female	3/4	1.31	—	RA-716-14F-SS		
<b>REDUCING BUSHINGS</b>							
1/4	1/8	7/8	1.09	RB-14-18-BR	RB-14-18-SS		
1/2	1/8	7/8	1.09	RB-12-18-BR	RB-12-18-SS		
1/2	1/4	7/8	1.09	RB-12-14-BR	RB-12-14-SS		
3/4	1/2	1 1/8	1.17	RB-34-12-BR	RB-34-12-SS		
1	1/2	1 3/8	1.36	RB-1-12-BR	RB-1-12-SS		
1	3/4	1 3/8	1.36	RB-1-34-BR	RB-1-34-SS		
1 1/4	3/4	1 3/4	1.48	—	RB-114-34-CS*		
1 1/4	1	1 3/4	1.48	—	RB-114-1-CS*		
1 1/2	1	2	1.56	—	RB-112-1-CS*		

## OMEGALOK® COMPRESSION FITTINGS

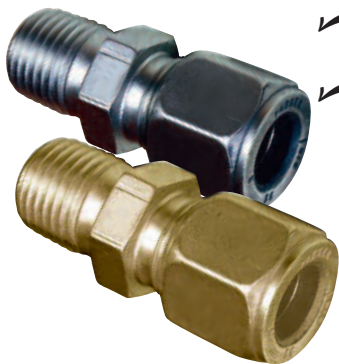

- ✓ Ferrule Design for Positive Pressure Seal
  - ✓ Heavy Duty Construction in Stainless Steel or Brass
  - ✓ For Protection Tube Diameters 1/16" up to 1/2"
- For metric compression fittings see page C-8.

\* Fittings are available only in carbon steel.  
Ordering Example: RB-12-14-SS, stainless steel 1/2 male and 1/4 female reducing bushing,

**MOST POPULAR  
MODELS HIGHLIGHTED!**

COMPRESSION FITTINGS

## To Order (Specify Model Number)

PROTECTION TUBE OD in.	MALE Th'd NPT	LENGTH mm (in)	BRASS		316 SS	
			MODEL NO.	MODEL NO.		
1/16	1/16	24.6 (0.97)	N/A	SSLK-116-116		
1/16	1/8	26.2 (1.03)	BRLK-116-18	SSLK-116-18		
1/8	1/8	30.0 (1.18)	BRLK-18-18	SSLK-18-18		
1/8	1/4	44.2 (1.74)	BRLK-18-14	SSLK-18-14		
3/16	1/8	31.0 (1.22)	BRLK-316-18	SSLK-316-18		
3/16	1/4	46.0 (1.81)	BRLK-316-14	SSLK-316-14		
1/4	1/8	32.8 (1.29)	BRLK-14-18	SSLK-14-18		
1/4	1/4	37.6 (1.48)	BRLK-14-14	SSLK-14-14		
5/16	1/4	39.1 (1.54)	N/A	SSLK-516-14		
3/8	1/4	40.4 (1.59)	BRLK-38-14	SSLK-38-14		
3/8	3/8	40.4 (1.59)	BRLK-38-38	SSLK-38-38		
3/8	1/2	46.0 (1.81)	BRLK-38-12	SSLK-38-12		
1/2	1/2	49.3 (1.94)	BRLK-12-12	SSLK-12-12		

Note: PTFE can only be used with stainless steel compression fittings.  
Ordering Example: BRLK-18-18, brass 1/8 NPT compression fitting for 1/8" OD protection tubes,

## Replacement Ferrules - (pkg of 10)

TUBE OD	BRASS	STAINLESS STEEL	PTFE
1/16	B-FER-1/16	S-FER-1/16	T-FER-1/16
1/8	B-FER-1/8	SS-FER-1/8	T-FER-1/8
3/16	B-FER-3/16	SS-FER-3/16	T-FER-3/16
1/4	B-FER-1/4	SS-FER-1/4	T-FER-1/4
5/16	B-FER-5/16	SS-FER-5/16	T-FER-5/16
3/8	B-FER-3/8	SS-FER-3/8	T-FER-3/8
1/2	B-FER-1/2	SS-FER-1/2	T-FER-1/2

# METRIC THREAD ADAPTORS



Brass

Stainless Steel



CONVERT IMPERIAL AND METRIC THREADS

**MOST POPULAR MODELS HIGHLIGHTED!**

To Order (Specify Model Number)


FEMALE NPT	MALE BSPT*	FLATS mm	LENGTH mm	BRASS		STAINLESS STEEL	
				MODEL NO.	MODEL NO.		
1/8	1/8-28	14	27.7	MTA1-1/8-1/8-BR	MTA1-1/8-1/8-SS		
1/4	1/4-19	19	36.1	MTA1-1/4-1/4-BR	MTA1-1/4-1/4-SS		
3/8	3/8-19	22	38.1	MTA1-3/8-3/8-BR	MTA1-3/8-3/8-SS		
1/2	1/2-14	27	49.3	MTA1-1/2-1/2-BR	MTA1-1/2-1/2-SS		
3/4	3/4-14	34	51.3	MTA1-3/4-3/4-BR	MTA1-3/4-3/4-SS		
1	1-11	41	58.4	MTA1-1-1-BR	MTA1-1-1-SS		
BSPT*	NPT						
1/4-19	1/4	19	36.3	MTA2-1/4-1/4-BR	MTA2-1/4-1/4-SS		
3/8-19	3/8	22	38.4	MTA2-3/8-3/8-BR	MTA2-3/8-3/8-SS		
1/2-14	1/2	27	49.8	MTA2-1/2-1/2-BR	MTA2-1/2-1/2-SS		
NPT	BSPP						
1/8	1/8-28	14	25.1	-	MTA3-1/8-1/8-SS		
1/4	1/4-19	19	33.5	MTA3-1/4-1/4-BR	MTA3-1/4-1/4-SS		
3/8	3/8-19	22	35.8	MTA3-3/8-3/8-BR	MTA3-3/8-3/8-SS		
1/2	1/2-14	27	44.2	MTA3-1/2-1/2-BR	MTA3-1/2-1/2-SS		
3/4	3/4-14	34	48.0	MTA3-3/4-3/4-BR	MTA3-3/4-3/4-SS		
1	1-11	41	53.3	MTA3-1-1-BR	MTA3-1-1-SS		
BSPP	NPT						
1/4-19	1/4	19	27.4	MTA4-1/4-1/4-BR	MTA4-1/4-1/4-SS		
3/8-19	3/8	22	32.3	MTA4-3/8-3/8-BR	MTA4-3/8-3/8-SS		
1/2-14	1/2	27	41.9	MTA4-1/2-1/2-BR	MTA4-1/2-1/2-SS		

\* ISO 228/1, BS 2779.

Ordering Examples: MTA1-1/8-1/8-BR, brass 1/8 NPT female to 1/8-28 BSPT male, MTA1-1/8-1/8-SS, stainless steel thread adaptor,

# METRIC OMEGALOK® COMPRESSION FITTINGS

FOR METRIC PROBES AND PROTECTION TUBES

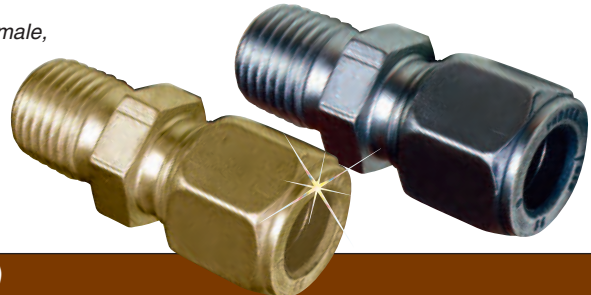

To Order Metric Compression Fittings (Specify Model Number)

Protection Tube OD	Male Th's	Th'd Type	Metric Protection Tube/NPT Thread				Metric Protection Tube/ BSP Taper Thread				Metric Protection Tube/ BSP Parallel Thread			
			Brass		316 Stainless Steel		Brass		316 Stainless Steel		Brass		316 Stainless Steel	
			Model No.	Model No.	Model No.	Model No.	Model No.	Model No.	Model No.	Model No.	Model No.	Model No.	Model No.	
1.5 mm	1/8	NPT	BRLK-M15-18	SSLK-M15-18	BSPPT	BRLK-M15-18T	SSLK-M15-18T	BSPPT	BRLK-M15-18P	SSLK-M15-18P				
3.0 mm	1/8	NPT	BRLK-M30-18	SSLK-M30-18	BSPPT	BRLK-M30-18T	SSLK-M30-18T	BSPPT	BRLK-M30-18P	SSLK-M30-18P				
4.5 mm	1/8	NPT	BRLK-M45-18	SSLK-M45-18	BSPPT	BRLK-M45-18T	SSLK-M45-18T	—	N/A	N/A				
6.0 mm	1/8	NPT	BRLK-M60-18	SSLK-M60-18	BSPPT	BRLK-M60-18T	SSLK-M60-18T	—	N/A	N/A				
3.0 mm	1/4	NPT	BRLK-M30-14	SSLK-M30-14	BSPPT	BRLK-M30-14T	SSLK-M30-14T	BSPPT	BRLK-M30-14P	SSLK-M30-14P				
4.5 mm	1/4	NPT	BRLK-M45-14	SSLK-M45-14	BSPPT	BRLK-M45-14T	SSLK-M45-14T	—	N/A	N/A				
6.0 mm	1/4	NPT	BRLK-M60-14	SSLK-M60-14	BSPPT	BRLK-M60-14T	SSLK-M60-14T	BSPPT	BRLK-M60-14P	SSLK-M60-14P				
8.0 mm	1/4	NPT	BRLK-M80-14	SSLK-M80-14	BSPPT	BRLK-M80-14T	SSLK-M80-14T	—	N/A	N/A				
3.0 mm	3/8	—	N/A	SSLK-M30-38	—	N/A	SSLK-M30-38T	—	N/A	SSLK-M30-38P				
6.0 mm	3/8	NPT	BRLK-M60-38	SSLK-M60-38	BSPPT	BRLK-M60-38T	SSLK-M60-38T	BSPPT	BRLK-M60-38P	SSLK-M60-38P				
3.0 mm	1/2	—	N/A	SSLK-M30-12	BSPPT	BRLK-M30-12T	SSLK-M30-12T	BSPPT	BRLK-M30-12P	SSLK-M30-12P				
4.5 mm	1/2	—	N/A	SSLK-M45-12	BSPPT	BRLK-M45-12T	SSLK-M45-12T	BSPPT	BRLK-M45-12P	SSLK-M45-12P				
6.0 mm	1/2	NPT	BRLK-M60-12	SSLK-M60-12	BSPPT	BRLK-M60-12T	SSLK-M60-12T	BSPPT	BRLK-M60-12P	SSLK-M60-12P				
8.0 mm	1/2	NPT	BRLK-M80-12	SSLK-M80-12	BSPPT	BRLK-M80-12T	SSLK-M80-12T	—	N/A	N/A				

Note: PFA can only be used with stainless steel compression fittings.

Ordering Examples: BRLK-M30-18, brass 1/8 NPT thread compression fitting for 3.0 mm protection tube OD, BRLK-M60-18, compression fitting,

ACCESSORIES



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters