


## Cat5e Patch Cables

### Cat5e UTP Extension Cables

Part No: See Chart

The UTP extensions avoid the necessity of replacing an existing cable when additional length is required. Available in both Cat.5E and Cat.6 versions, each assembly is quality manufactured and fully tested before shipment.

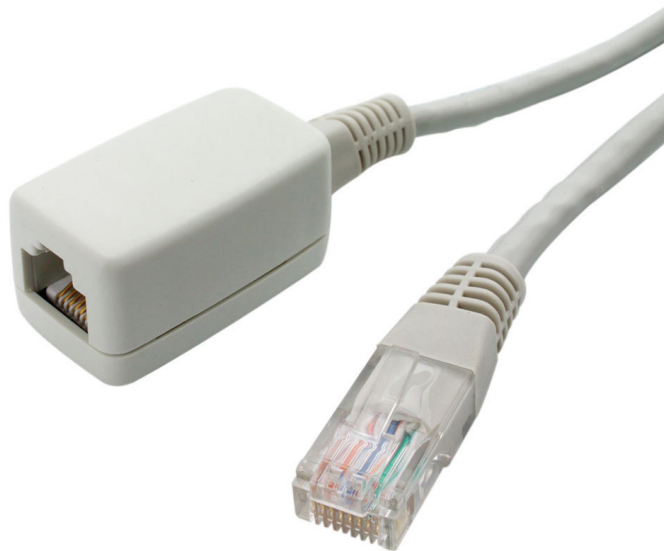

#### Features & Benefits

- Both Cat.5E and Cat.6 versions manufactured using quality components
- Plug to socket cable allowing the extension of an already sited patch cable
- Useful network link cables available in various lengths, standard colour is beige
- Fully tested UTP cables, wired on a straight through pin 1 to 1 configuration

Part Number	Product Description
1963-0.5	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 0.5Mtr
1963-1	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 1Mtr
1963-2	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 2Mtr
1963-3	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 3Mtr
1963-8	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 8Mtr
1963-10	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 10Mtr
1963-15	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 15Mtr

# VIDEK

## Cat5e Patch Cables Cat5e UTP Extension Cables

Part No: See Chart

Part Number	Product Description
1963-20	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 20Mtr
1963-30	VIDEK Cat5e UTP RJ45 Plug to Socket Extension Cable Beige 30Mtr

### Material

- 1. Housing : ABS, UL 94V-0. Outward Matt, Grey Colour
- 2. IDC:
  - 2-1 IDC Housing : Polycarbonate, UL 94V-2, KRONE dual
  - 2-2 IDC Terminal material & finished : Phosphor Bronze with 50-60 micro-inch Tin-Lead plated
- 3. Molding Type : Narrow Molded, PVC 70P, Grey Colour
- 4. Cable : min. Cat.5e Unshielded Twisted Pair, 24AWG Stranded conductor, PVC Jacket with Grey Colour
- 5. RJ45 Plug :
  - 5-1. Housing & insert : Polycarbonate, UL 94V-2, Transparent Colour
  - 5-2. Contact material : Phosphor Bronze with 50-60 micro-inch Nickel plated
  - 5-3. Contact finished : min. 50 micro-inch Gold plated on contact area

