

[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [04015SS-12N-AL-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

DC Axial Fans - 04015SS-12N-AL-00

[Get a sample](#)

Inventory


Distributor	Availability	
Digi-Key Electronics	340	Buy Now

Resources



Specification Sheet

Series
Data
Sheet

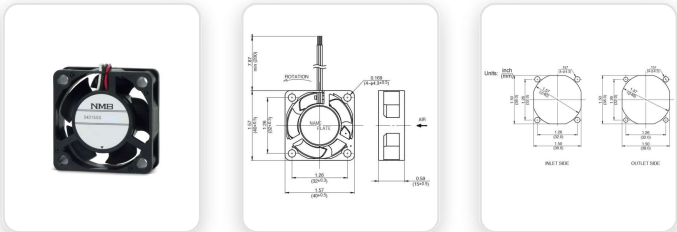

Specifications

Category	DC Axial Fans
Part Number	04015SS-12N-AL-00
Frame Width [mm]	40
Frame Height [mm]	40
Frame Depth [mm]	15

Max. Air Flow [CFM]	7.4
Max. Air Flow [m3 per min]	0.21
Max. Static Pressure [In H2O]	0.27
Max. Static Pressure [Pa]	68
Fan Speed [RPM]	8300
Noise [dB]	32
Life Expectancy [L10]	40 degree C 40,000 Hours
Bearing Type	Sleeve Bearing
Nominal Voltage [V]	12
Operating Voltage - Lower [V]	6
Operating Voltage - Upper [V]	13.8
Current [A]	0.06