

[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [08020SA-24K-AA-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

DC Axial Fans - 08020SA-24K-AA-00

 
[Get a sample](#)


Resources

Specification Sheet	Series Data Sheet
Certificates	RoHS Certificate





←



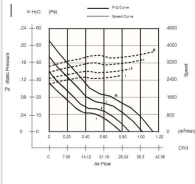



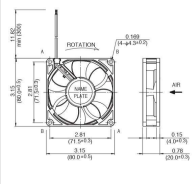

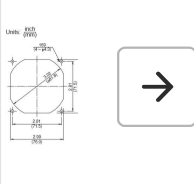

→

Specifications

Category	DC Axial Fans
Part Number	08020SA-24K-AA-00
Frame Width [mm]	80
Frame Height [mm]	80
Frame Depth [mm]	20

Max. Air Flow [CFM]	31.1
Max. Air Flow [m3 per min]	0.88
Max. Static Pressure [In H2O]	0.11
Max. Static Pressure [Pa]	28.5
Fan Speed [RPM]	2900
Noise [dB]	31
Life Expectancy [L10]	60 degree C 40,000 Hours
Bearing Type	Ball Bearing
Nominal Voltage [V]	24
Operating Voltage - Lower [V]	9
Operating Voltage - Upper [V]	27.6
Current [A]	0.06

Input Power [W]	1.4
Mass [g]	80
Tach / Locked Rotor Output	No
Status	Active

PRODUCTS[See All Products](#) →[Find A Distributor](#)[Find a Sales Representative](#)**INDUSTRIES**[See All Industries](#)[Automotive](#)[Industrial](#)[Medical](#)[Consumer Technology](#)[Smart City](#)[Lighting Innovations](#)**RESOURCES**[See All Resources](#) →[Application Notes & Whitepapers](#)[Latest News](#)[Videos](#)**CONTACT****NMB Technologies Corporation****(248) 919-2250****info@nmbtc.com**

Have A Question?

Our precision component experts can help you find the right solutions.

[Contact Us Today](#)[Find A Distributor](#)[Find Sales Rep For Fans](#) →

NMB Technologies Corporation © 2021. All Rights Reserved.

[Company](#)[Careers](#)[Sitemap](#)[Privacy Policy](#)[Terms of use](#)

