
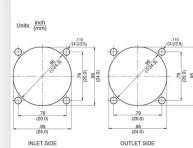


[Update related to COVID-19. Learn More →](#)**MinebeaMitsumi**
Passion to Create Value through Difference[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > **02510SS-05J-AA-00**[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

DC Axial Fans - 02510SS-05J-AA-00

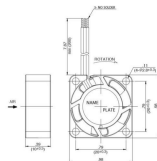

Resources

Specification Sheet	Series Data Sheet
---------------------	-----------------------------------

Specifications

Category	DC Axial Fans
Part Number	02510SS-05J-AA-00
Frame Width [mm]	25
Frame Height [mm]	25
Frame Depth [mm]	10
Max. Air Flow [CFM]	1.13
Max. Air Flow [m3 per min]	0.032
Max. Static Pressure [In H2O]	0.046
Max. Static Pressure [Pa]	11.6
Fan Speed [RPM]	5500
Noise [dB]	22
Life Expectancy [L10]	30,000 hours at 40C
Bearing Type	Sleeve Bearing

11/18/21, 2:11 PM

02510SS-05J-AA-00 | DC Axial Fans | NMB

Bearing Type	Sleeve Bearing
Nominal Voltage [V]	5
Operating Voltage - Lower [V]	4.5
Operating Voltage - Upper [V]	5.5
Current [A]	0.04
Input Power [W]	0.2
Mass [g]	8
Tach / Locked Rotor Output	No
Status	Active

Have A Question?

Our precision component experts can help you find the right solutions.

Contact Us Today

Find A Distributor

Find Sales Rep For Fans →

PRODUCTS

See All Products →

Find A Distributor

Find a Sales Representative