
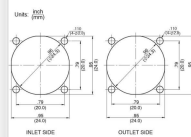


[Update related to COVID-19. Learn More →](#)**MinebeaMitsumi**
Passion to Create Value through Difference[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > **02510SS-12P-AL-00**[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

DC Axial Fans - 02510SS-12P-AL-00

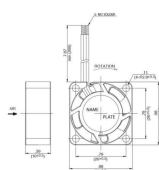

Get a sample

Resources

| | |
|---------------------|-----------------------------------|
| Specification Sheet | Series Data Sheet |
|---------------------|-----------------------------------|

Specifications

| | |
|-------------------------------|--------------------------|
| Category | DC Axial Fans |
| Part Number | 02510SS-12P-AL-00 |
| Frame Width [mm] | 25 |
| Frame Height [mm] | 25 |
| Frame Depth [mm] | 10 |
| Max. Air Flow [CFM] | 2.65 |
| Max. Air Flow [m3 per min] | 0.08 |
| Max. Static Pressure [In H2O] | 0.27 |
| Max. Static Pressure [Pa] | 68 |
| Fan Speed [RPM] | 13000 |
| Noise [dB] | 28.5 |
| Life Expectancy [L10] | 40 degree C 30,000 Hours |
| Bearing Type | Sleeve Bearing |

| | |
|-------------------------------|----------------|
| Bearing Type | Sleeve Bearing |
| Nominal Voltage [V] | 12 |
| Operating Voltage - Lower [V] | 6 |
| Operating Voltage - Upper [V] | 13.8 |
| Current [A] | 0.07 |
| Input Power [W] | 0.8 |
| Mass [g] | 8 |
| Tach / Locked Rotor Output | Locked Rotor |
| Status | Active |

Have A Question?

Our precision component experts can help you find the right solutions.

Contact Us Today

Find A Distributor

Find Sales Rep For Fans →

PRODUCTS

See All Products →

Find A Distributor

Find a Sales Representative