

Update related to COVID-19. Learn More →



Products

Industries

About

Resources

Blog

Contact us

Find A Distributor

Home > Products > Cooling Fans > DC Axial Fans > 03510SS-12N-AL-00

← Back To DC Axial Fans

Have a question about this product?



## DC Axial Fans - 03510SS-12N-AL-00



Get a sample

### Inventory



Distributor	Availability	
Digi-Key Electronics	173	<a href="#">Buy Now</a>

### Resources



Specification Sheet

Series  
Data  
Sheet

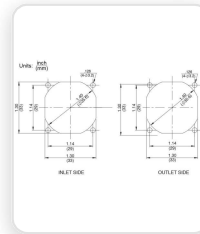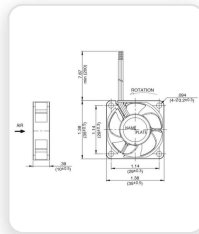

## Specifications

<b>Category</b>	DC Axial Fans
<b>Part Number</b>	03510SS-12N-AL-00
<b>Frame Width [mm]</b>	35
<b>Frame Height [mm]</b>	35
<b>Frame Depth [mm]</b>	10

<b>Max. Air Flow [CFM]</b>	5.7
<b>Max. Air Flow [m3 per min]</b>	0.16
<b>Max. Static Pressure [In H2O]</b>	0.23
<b>Max. Static Pressure [Pa]</b>	56.3
<b>Fan Speed [RPM]</b>	10,000
<b>Noise [dB]</b>	27
<b>Life Expectancy [L10]</b>	30,000 hours at 40C
<b>Bearing Type</b>	Sleeve Bearing
<b>Nominal Voltage [V]</b>	12
<b>Operating Voltage - Lower [V]</b>	6
<b>Operating Voltage - Upper [V]</b>	13.2
<b>Current [A]</b>	0.7