
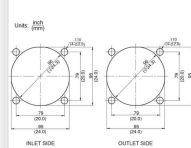


[Update related to COVID-19. Learn More →](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [02510SS-05M-AT-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

## DC Axial Fans - 02510SS-05M-AT-00

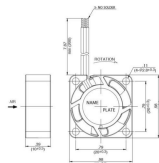

Get a sample

Resources

Specification Sheet	<a href="#">Series Data Sheet</a>
---------------------	-----------------------------------

Specifications

Category	DC Axial Fans
Part Number	02510SS-05M-AT-00
Frame Width [mm]	25
Frame Height [mm]	25
Frame Depth [mm]	10
Max. Air Flow [CFM]	1.94
Max. Air Flow [m3 per min]	0.055
Max. Static Pressure [In H2O]	0.14
Max. Static Pressure [Pa]	35
Fan Speed [RPM]	9500
Noise [dB]	21.5
Life Expectancy [L10]	30,000 hours at 40C
Bearing Type	Sleeve Bearing

Bearing Type	Sleeve Bearing
Nominal Voltage [V]	5
Operating Voltage - Lower [V]	4.5
Operating Voltage - Upper [V]	5.5
Current [A]	0.08
Input Power [W]	0.4
Mass [g]	8
Tach / Locked Rotor Output	Tach Output
Status	Active

# Have A Question?

Our precision component experts can help you find the right solutions.

Contact Us Today

Find A Distributor

Find Sales Rep For Fans →

## PRODUCTS

See All Products →

Find A Distributor

Find a Sales Representative