

[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [04015SS-24M-AL-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?




[Ask Our Experts →](#)

DC Axial Fans - 04015SS-24M-AL-00

[Get a sample](#)

Resources

[Specification Sheet](#)[Series
Data
Sheet](#)

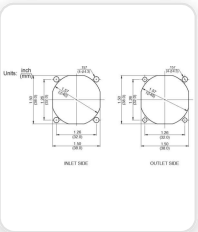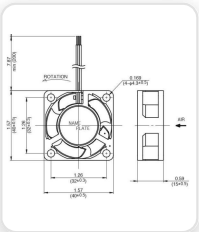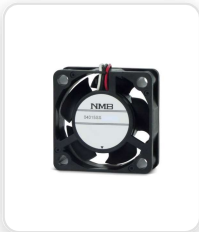

Specifications

Category	DC Axial Fans
Part Number	04015SS-24M-AL-00
Frame Width [mm]	40
Frame Height [mm]	40
Frame Depth [mm]	15

Max. Air Flow [CFM]	6.4
Max. Air Flow [m3 per min]	0.18
Max. Static Pressure [In H2O]	0.21
Max. Static Pressure [Pa]	52
Fan Speed [RPM]	7300
Noise [dB]	29
Life Expectancy [L10]	40 degree C 40,000 Hours
Bearing Type	Sleeve Bearing
Nominal Voltage [V]	24
Operating Voltage - Lower [V]	10
Operating Voltage - Upper [V]	25.2
Current [A]	0.04