

[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [03510SS-12L-AT-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?



[Ask Our Experts →](#)

DC Axial Fans - 03510SS-12L-AT-00

[Get a sample](#)

Resources

[Specification Sheet](#)[Series
Data
Sheet](#)

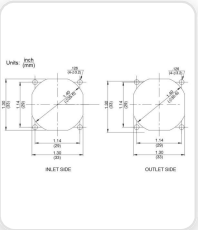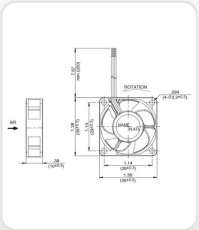

Specifications

Category	DC Axial Fans
Part Number	03510SS-12L-AT-00
Frame Width [mm]	35
Frame Height [mm]	35
Frame Depth [mm]	10

Max. Air Flow [CFM]	3.88
Max. Air Flow [m3 per min]	0.11
Max. Static Pressure [In H2O]	0.124
Max. Static Pressure [Pa]	30.9
Fan Speed [RPM]	7000
Noise [dB]	19
Life Expectancy [L10]	30,000 hours at 40C
Bearing Type	Sleeve Bearing
Nominal Voltage [V]	12
Operating Voltage - Lower [V]	6
Operating Voltage - Upper [V]	13.2
Current [A]	0.04