

[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [04015SS-24M-AT-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?



[Ask Our Experts →](#)

## DC Axial Fans - 04015SS-24M-AT-00

[Get a sample](#)

### Resources

[Specification Sheet](#)[Series  
Data  
Sheet](#)

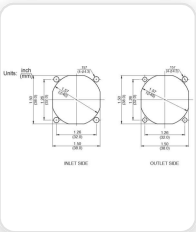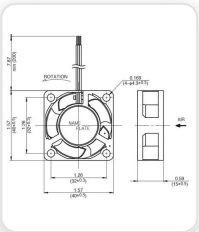

Specifications

Category	DC Axial Fans
Part Number	04015SS-24M-AT-00
Frame Width [mm]	40
Frame Height [mm]	40
Frame Depth [mm]	15

<b>Max. Air Flow [CFM]</b>	6.4
<b>Max. Air Flow [m3 per min]</b>	0.18
<b>Max. Static Pressure [In H2O]</b>	0.21
<b>Max. Static Pressure [Pa]</b>	52
<b>Fan Speed [RPM]</b>	7300
<b>Noise [dB]</b>	29
<b>Life Expectancy [L10]</b>	40 degree C 40,000 Hours
<b>Bearing Type</b>	Sleeve Bearing
<b>Nominal Voltage [V]</b>	24
<b>Operating Voltage - Lower [V]</b>	10
<b>Operating Voltage - Upper [V]</b>	25.2
<b>Current [A]</b>	0.04