


[Update related to COVID-19. Learn More →](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [03010SS-05M-AT-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

DC Axial Fans - 03010SS-05M-AT-00

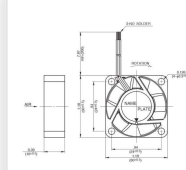

Get a sample

Specifications

Category	DC Axial Fans
Part Number	03010SS-05M-AT-00
Frame Width [mm]	30
Frame Height [mm]	30
Frame Depth [mm]	10
Max. Air Flow [CFM]	3.9
Max. Air Flow [m3 per min]	0.11
Max. Static Pressure [In H2O]	0.19
Max. Static Pressure [Pa]	48
Fan Speed [RPM]	9500
Noise [dB]	26
Life Expectancy [L10]	40 degree C 30,000 Hours
Bearing Type	Sleeve Bearing
Nominal Voltage [V]	5
Operating Voltage - Lower [V]	4.5

Operating Voltage - Upper [V]	5.5
Current [A]	0.16
Input Power [W]	0.8
Mass [g]	8.5
Tach / Locked Rotor Output	Tach Output
Status	Active

Have A Question?

Our precision component experts can help you find the right solutions.

Contact Us Today

Find A Distributor

Find Sales Rep For Fans →

PRODUCTS

See All Products →

Find A Distributor

Find a Sales Representative

INDUSTRIES

See All Industries →

Automotive

[Automotive](#)

[Industrial](#)

[Medical](#)

[Consumer Technology](#)

[Smart City](#)

[Lighting Innovations](#)

RESOURCES

[See All Resources](#) →

[Application Notes & Whitepapers](#)

[Latest News](#)

[Videos](#)

CONTACT

NMB Technologies Corporation

[\(248\) 919-2250](#)

info@nmbtc.com

NMB Technologies Corporation © 2021. All Rights Reserved.

[Company](#)

[Careers](#)

[Sitemap](#)

[Privacy Policy](#)

[Terms of use](#)