


[Update related to COVID-19. Learn More →](#)[Products](#)[Industries](#)[About](#)[Resources](#)[Blog](#)[Contact us](#)[Find A Distributor](#)[Home](#) > [Products](#) > [Cooling Fans](#) > [DC Axial Fans](#) > [03010SS-12L-AL-00](#)[← Back To DC Axial Fans](#)

Have a question about this product?

[Ask Our Experts →](#)

DC Axial Fans - 03010SS-12L-AL-00

[Get a sample](#)

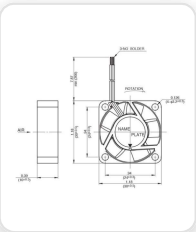

Specifications

Category	DC Axial Fans
Part Number	03010SS-12L-AL-00
Frame Width [mm]	30
Frame Height [mm]	30
Frame Depth [mm]	10

Max. Air Flow [CFM]	3.5
Max. Air Flow [m3 per min]	0.1
Max. Static Pressure [In H2O]	0.15
Max. Static Pressure [Pa]	38
Fan Speed [RPM]	8500
Noise [dB]	26
Life Expectancy [L10]	40 degree C 30,000 Hours
Bearing Type	Sleeve Bearing
Nominal Voltage [V]	12
Operating Voltage - Lower [V]	7
Operating Voltage - Upper [V]	13.2
Current [A]	0.06