



## Mounting Bracket 10/11x7mm 90° Steel,nickel-plated/1x ø3.2mm/M3

Part No.: 014.86.313

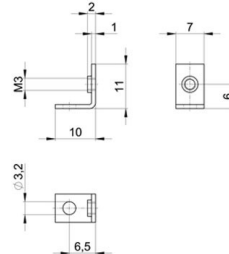

Material: Steel  
Finish: Nickel-plated  
Design: Gestanzt  
Leg Length 2 [mm]: 10  
Width / Outer Dia. [mm]: 7  
Model: Brackets 90°  
Hole Dia./Thread #1: Ø 3.2 mm - 1/8"  
Hole Dia./Thread #2: M3  
Leg Length [mm]: 11  
Material Group: Steel  
Conformities :

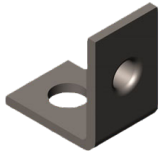

Looking for some advice for your specific situation?  
If so, please don't hesitate to e-mail us at [products@ettinger.de](mailto:products@ettinger.de)

Contact:  
[www.ettinger.de](http://www.ettinger.de)  
[info@ettinger.de](mailto:info@ettinger.de)  
Tel.: +49-8104/662388  
Fax: +49-8104/662399

Delivery address:  
Ettinger GmbH  
Ottostraße 5  
85649 Hofolding  
Germany