

CREALITY



BL Touch Probes 1PC

MFR: 4004010126

Product Information

Stable Performance

High Performance

Intelligence

3D PRINTER CREALITY

BLTouch Probes

Imported from South Korea

Stable performance High performance Intelligence

BLTouch Probes

BLTouch

VS

The comparison of BLTouch with other common probes

20%

Improved accuracy by 20%

30%

Improved stability by 30%

 


High precision, intelligent sensor

BLTouch with high precision and low power consumption can automatically detect leveling and output accurate data. The standard deviation is only 0.005mm, making leveling more convenient

0-4_{mm}
Detection zone

0.005_{mm}
Standard deviation



Auto detection
and leveling



The above is the installation diagram, for reference only.

Wide application, strong compatibility


Compatible with ABS, PLA, glass, metal, plastic and all materials. Support more filaments and apply to every control board of 3D printer

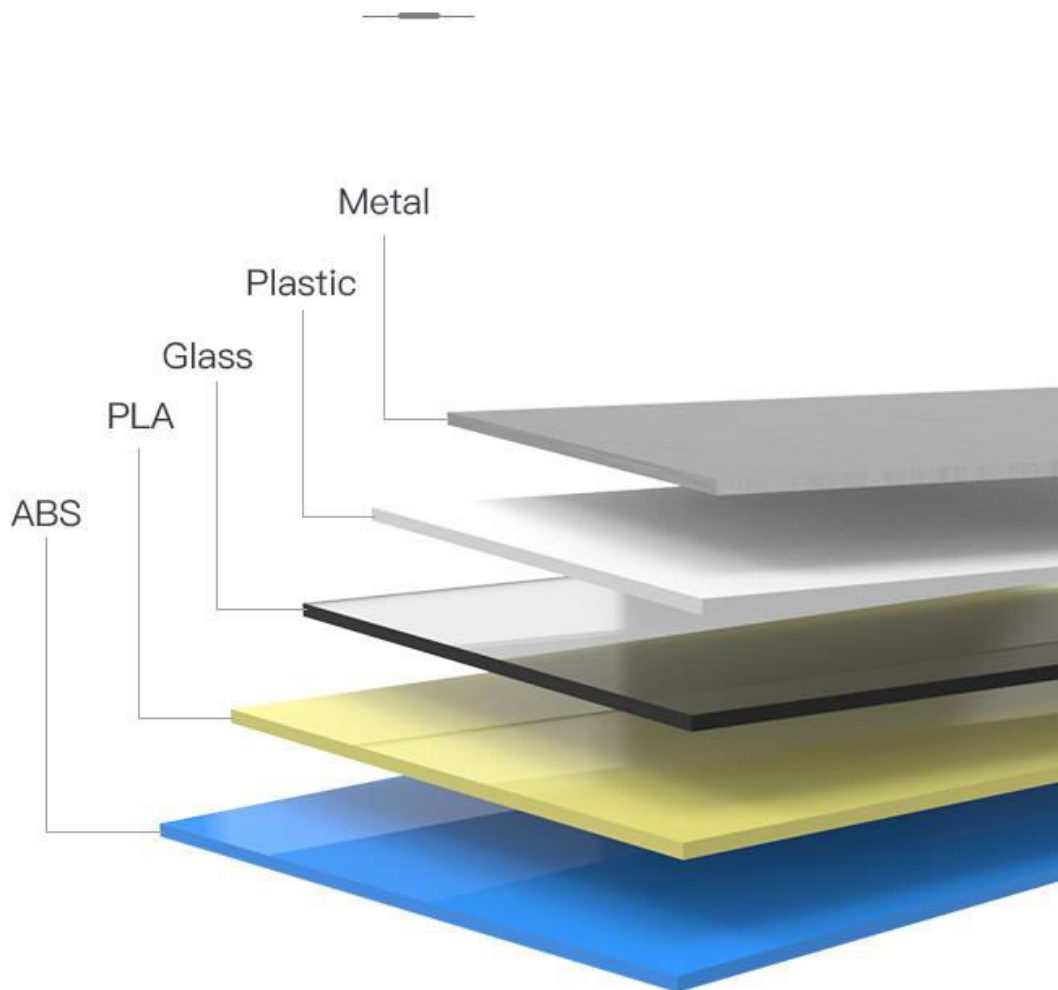

Do not use any light and not approach any inductance / capacitance sensor
Provide high precision through Hall Effect control. Therefore, the platform board
can be selected at will.

Low power consumption

In standby mode, no matter whether it is pulled out or retracted, the standby current of solenoid valve without current flow is less than 15ma, while in working mode, it suddenly rises to 100ms / 300ma. Low power consumption and avoiding heating problems

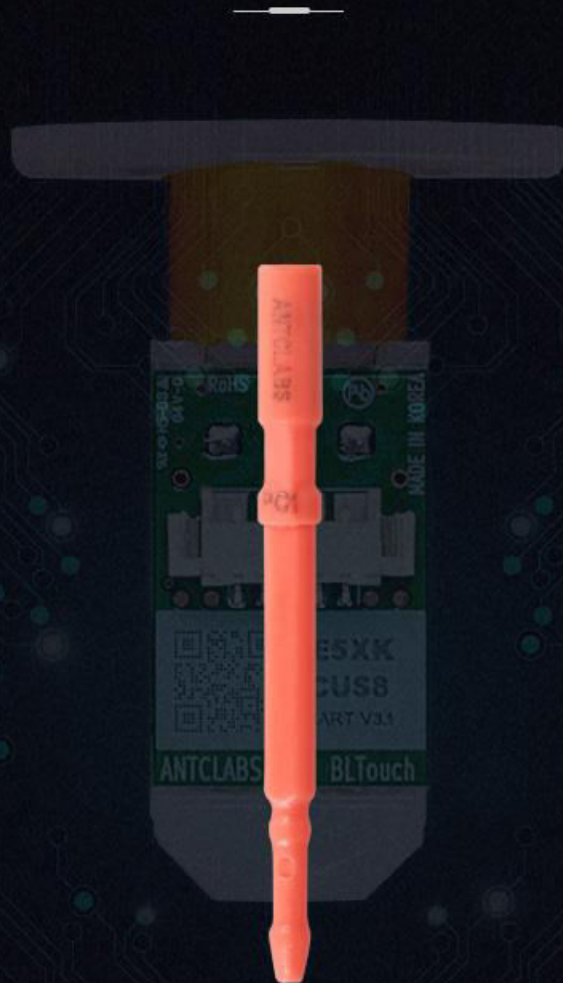

Please keep away from magnetic components such as strong magnet, motor and fan for installation

Product information

Product name: BLTouch Probes

Applicable model: BLTOUCH

Product size: 35*3.0*1.6mm **Net weight :** 0.1g

Package size: 38*5.5*11.5mm **Gross weight :** 1.7g
