

CREALITY



Ender-3 Max Repair Kit

MFR: 4006010009

Product Information

Complete Maintenance Equipment

Cables and wires



XE motor line
X: L900mm
Y: L1000mm



Y motor line L550mm



Z motor line L400mm



Power wire L300mm



Power wire L350mm



Hot bed wire L900mm



Power wire
L90mm

Fan extension cable
L100mm

Display line
L480mm



Power wire L200mm

Power wire L170mm

Power wire L200mm

Screws list

Hexagon socket head screw



(M5*8)*1、(M5*10)*1、(M5*30)*1、(M5*40)*1、(M8*25)*1

(M4*6)*1、(M4*8)*1、(M4*12)*1、(M4*16)*1、(M4*20)*1、(M4*25)*1

(M3*4)*1、(M3*6)*2、(M2*8)*1、(M3*10)*1、(M3*14)*1

Hexagon socket countersunk head screws




(M4*18)*1, (M3*40)*1, (M3*18)*1, (M3*14)*1, (M3*10)*1, (M3*8)*1

Others



Cross recessed countersunk head screw (M4*45)*1,
Hexagon socket set screw with flat end (M3*3)*2,
Cross round head screw with medium (M3*4)*1,
Cross groove pan head tapping screw (ST3*8)*1
Cross groove pan head tapping screw (ST3*6)*1,
Phillips pan head screw (M1.7*8)*1

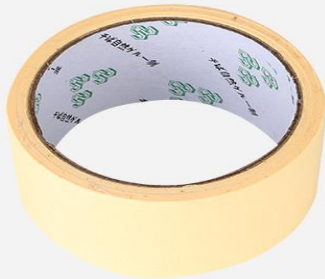

Textured paper*1



Black nylon cable tie*1

Item Name	Spec.	Quantity	Unit
Hexagon socket countersunk head screw	M3*18, SUS304, , ROHS	1.00	PCS
Hexagon socket countersunk head screw	M3*40, 40CR, black, ROHS	1.00	PCS
Hexagon socket countersunk head screw	M4*18, 40CR, black, ROHS	1.00	PCS
Hexagon socket countersunk head screw	M3*14, SUS304, , ROHS	1.00	PCS
Hexagon socket countersunk head screw	M3*10, SUS304, , ROHS	1.00	PCS
Hexagon socket countersunk head screw	M3*8, SUS304, , ROHS	2.00	PCS
Hexagon socket flat round head screw	M3*14, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M8*25, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M5*40, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M5*30, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M5*10, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M5*8, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M4*20, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M4*16, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M4*12, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M4*8, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M4*6, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M3*16, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M3*10, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M3*6, SUS304, , ROHS	2.00	PCS
Hexagon socket flat round head screw	M3*4, SUS304, , ROHS	1.00	PCS
Hexagon socket head screw	M5*65, 40CR, black, ROHS	1.00	PCS
Hexagon socket head screw	M4*18, SUS304, , ROHS	1.00	PCS
Hexagon socket head screw	M4*50, 40CR, black, ROHS	1.00	PCS
Hexagon socket head screw	M4*20, SUS304, , ROHS	1.00	PCS
Hexagon socket head screw	M5*25, 40CR, black, ROHS	1.00	PCS
Hexagon socket head screw	M4*16, SUS304, , ROHS	1.00	PCS
Hexagon socket head screw	M4*8, SUS304, , ROHS	1.00	PCS
Hexagon socket head screw	M3*18, SUS304, , ROHS	1.00	PCS
Hexagon socket head screw	M2*8, 40CR, black, ROHS	1.00	PCS
Cross recessed pan head tapping screw	ST3*6, SUS304, , ROHS	1.00	PCS
Cross recessed pan head tapping screw	ST3*8, SUS304, , ROHS	1.00	PCS
Hexagon socket head spring pad set screw	M5*40, 40CR, black, ROHS	2.00	PCS
Cross recessed round head with medium screw	M3*4, SUS304, , ROHS	1.00	PCS
Cross recessed pan head screw	M1.7*8, SUS304, , ROHS	1.00	PCS
Hexagon socket set screw with flat end	M3*3, 40CR, black, ROHS	2.00	PCS
Black nylon tie	4*150mm, black	100.00	PCS
textured paper	W50	1.00	PCS
valve bag	15cm*20cm*8, PE	3.00	PCS
Cross recessed countersunk head screws	M4*45, SUS304, , ROHS	1.00	PCS
Hexagon socket flat round head screw	M4*25, SUS304, , ROHS	1.00	PCS
power line	Power supply silicone wire, 1P yellow green cable, 1007, 18AWG, L170mm 4.0 U shape terminal and 4.8 inserted spring terminal, ROHS	1.00	PCS
power line	Power supply silicone wire, 1P black cable, 3135, 16AWG, L200mm 4.0 U shape terminal and 4.8 inserted spring terminal, ROHS	1.00	PCS
power line	Power supply silicone wire, 1P red cable, 3135, 16AWG, L90mm	1.00	PCS
power line	Power supply silicone wire, 2P red black cable, 3135, 14AWG, L350mm one XT60 female terminal	1.00	PCS
power line	Power supply silicone wire, 2P red black cable, 3135, 14AWG, L300mm XT60 male terminal and 4.0 U shape terminal, ROHS	1.00	PCS
power line	Power supply silicone wire, 1P red cable, 3135, 16AWG, L170mm, 4.0 U shape terminal and 4.8 inserted spring terminal, ROHS	1.00	PCS
hotbed line	Power supply silicone wire, 2P red black doubling, 3135, 15AWG, L900mm	1.00	PCS
motor limit line	Y-axis motor limit line, 6P black coupling, 1007, 24AWG 4P L550mm, XH2.54-4P terminal and PH2.0-6P terminal 2P L550mm, XH2.54-2P terminal and XH2.54-3P terminal	1.00	PCS
motor limit line	Z-axis motor limit line, 6P black coupling, 1007, 24AWG 4P L400mm, XH2.54-4P terminal and PH2.0-6P terminal 2P L300mm, XH2.54-2P terminal and XH2.54-3P terminal	1.00	PCS
motor limit line	XE-axis motor limit line, 6P black coupling, 1007, 24AWG 4P L900mm, XH2.54-4P terminal and PH2.0-6P terminal 6P black coupling, 1007, 24AW 4P L900mm, XH2.54-4P terminal and PH2.0-6P terminal 2P L1000mm, XH2.54-2P terminal and XH2.54-3P terminal	1.00	PCS
Display line	28AWG, L480mm, with IDC2.54-10P terminal	1.00	PCS
Fan extension cord	2P red black cable, 1007, 24AWG, L100mm	1.00	PCS