




Connectors > Circular Connectors > Circular Connector Accessories > Unscreened Circular Connector Backshells & Clamps > CPC CABLE CLAMPS

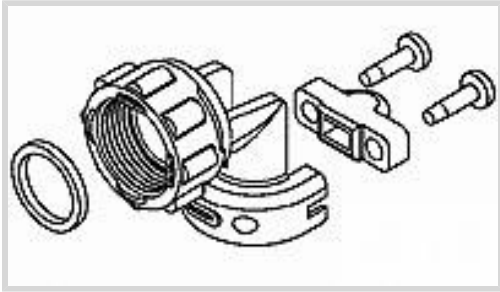

Backshell & Clamp Accessory Type: **Cable Clamp**
Compatible With Circular Connector Shell Size: **11**
Body Orientation: **Right Angle**
Accepts Cable Diameter (Max): **8.36 mm [.329 in]**
Protective Cover: **Without**

[All CPC CABLE CLAMPS \(25\)](#)

Features

Product Type Features

Product Type	Accessory
Backshell & Clamp Accessory Type	Cable Clamp
Protective Cover	Without

Body Features

Cable Clamp Material	Nylon
Cable Clamp Flammability Rating	UL 94V-0
Cable Clamp Color	Black

Mechanical Attachment

Screw Size	5-20
Screw Type	Self-Tapping
Screw & Hole Thread Size	5/8-24 UNEF-2B

Housing Features

Body Orientation	Right Angle
------------------	-------------

Dimensions

Accepts Cable Diameter (Max)	8.36 mm[.329 in]
------------------------------	------------------

Operation/Application

Compatible With Circular Connector Shell Size	11
---	----



Packaging Features

Packaging Quantity	1
Packaging Method	Individual

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUL 2021 (219) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-AM71-C83998M
CPC SERIES 2



TE Part # CAT-AM71-C83998Y
CPC SERIES 1 SEALED ONE-PIECE



TE Part # CAT-AM71-C83998J
CPC SERIES 1



TE Part # CAT-AM71-C83998K
CPC SERIES 6



TE Part # CAT-AM71-C83998F
CPC SERIES 1 POSTED




TE Part # CAT-AM71-C83998DD
CPC SERIES 2 POSTED




TE Part # 208130-1
CPC RECPT ASSEMBLY SIZE 11-4


Also in the Series | AMP CPC




Circular Connector Adapters(7)



Circular Connector Boots & Strain Relief(6)




Circular Connector Caps & Covers(16)




Circular Connector Hardware(3)




Circular Connector Keying Plugs(2)




Circular Connector Seals(36)




Circular Power Connectors(513)




Insertion & Extraction Tools(1)

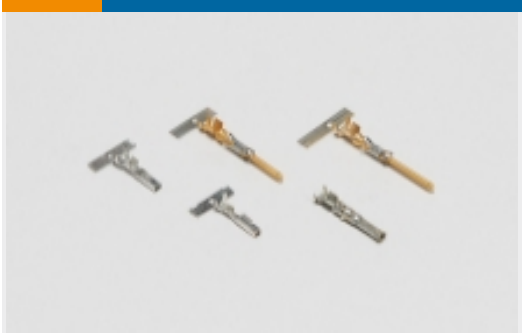

Power Contacts(6)



Sealing Sleeves(2)



Unscreened Circular Connector Backshells & Clamps(56)

Customers Also Bought



TE Part #325803-1
TERMINAL,AMPOWER 300MCM 3/8



TE Part #66564-8
TYPE III CONTACTS STRIP



TE Part #1-66358-9
III+ SKT,18-14,30AU/FL,STRIP



TE Part #36919
TERMINAL SOLIS RING 1/0 1/2



TE Part #211839-1
CPC RCPT SZ 23-24 W/THRD INSR

TE Part #36927
BODY SOLIS RING 3/0 3/8

TE Part #322259
TERMINAL,SOLIS R 300-350MCM

TE Part #1986221-1
CMC Plug assembly/ clamp kit 28-24

Documents

Product Drawings

R/A STRN RELIEF KIT,SZ 11,CPC

English

CAD Files

Customer View Model

ENG_CVM_CVM_796379-2_D.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_796379-2_D.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_796379-2_D.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Environmental Compliance

TE Material Declaration

English