

preLink RJ45 plug, IP20 Cat.6A L-35°

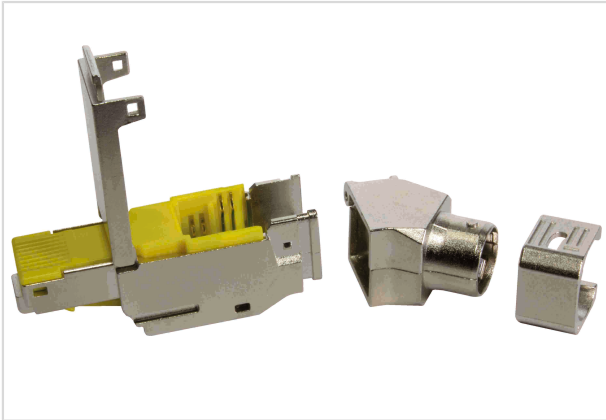


Image is for illustration purposes only. Please refer to product description.

Part number	20 82 101 0022
Specification	preLink RJ45 plug, IP20 Cat.6A L-35°
HARTING eCatalogue	https://b2b.harting.com/20821010022

Identification

Category	Connectors
Series	preLink®
Element	Connector
Specification	RJ45 35° angled

Version

Termination method	preLink® IDC insulation displacement termination
Gender	Male
Shielding	Shielded
Number of contacts	8
Coding	RJ45

Technical characteristics

Transmission characteristics	Cat. 6 _A Class E _A up to 500 MHz
Data rate	10 Mbit/s 100 Mbit/s 1 Gbit/s 2.5 Gbit/s 5 Gbit/s 10 Gbit/s
Limiting temperature	-40 ... +85 °C
Relative humidity	95 % Non-condensing (operation)
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20



Pushing Performance

Technical characteristics

Cable diameter	5 ... 9 mm
----------------	------------

Material properties

Material (insert)	Zinc die-cast, nickel-plated
-------------------	------------------------------

Specifications and approvals

Approvals	DNV GL
PROFINET	Yes

Commercial data

Packaging size	1
Net weight	26.46 g
Country of origin	Latvia
European customs tariff number	85366990
eCl@ss	27440101 Rectangular connectors (set)