


# Part Number: P-S12S21-M4RX

Voltage Test Station with Non-Flashing Voltage Indicator and Safe-Test Point, Horizontal Mount, UL Type 12 Housing

<https://shop.graceport.com/products/p-s12s21-m4rx>

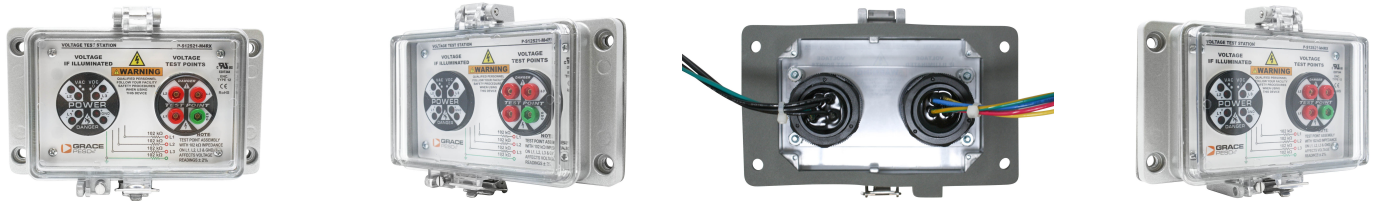

## Product Specifications

Component Details	
Part Number	P-S12S21-M4RX
Includes	Non-Flashing Voltage Indicator (R-3W-SR) and Safe-Test Point (R-3MT), UL Type 12 Housing, Horizontal Mount
Electrical Specifications	
Operational Temperature Range	-20°C to +55°C
Storage Temperature Range	-45°C to + 85°C
Operational Range AC Single/3-Phase	40-600VAC 50/60/400Hz
Operational Range DC or Stored Energy	30-600 VDC
Mechanical Specifications	
Enclosure Rating	IP65
Housing Size	M Size Housing
UL Type	Type 12
Latch	Type 304 Stainless Steel
Cover	Polycarbonate, UV rated
Mount	Horizontal






**Geometric Data**

Width	6.50 in
Height	3.78 in
Depth	1.60 in


**Commercial Data**

Country of Origin	US
Schedule B Code	8531.20.00400





**Approval Certifications**

Logo	Approval	Additional Text	Certificate Name	
	UL Underwriters Laboratories Inc.	Outlets UL Recognized for 15A	E207344	
<b>RoHS</b>	RoHS Restriction of Hazardous Substances		SS0002-0616-B-RH	
	CE European Conformity	INGR0516-A-00	SS0002-0616-A-CE	

**CAD Files**

File Format	
2D PDF File	

**Datasheets**

Name	
Voltage Test Station Datasheet	
Voltage Test Station Datasheet Spanish	
Voltage Test Station Installation Guide	
Voltage Test Station Single Phase Wiring Diagram	



**Don't see what you're looking for?**

Contact us at [sales@gracetechnologies.com](mailto:sales@gracetechnologies.com), call 1-800-280-9517 or visit [www.graceport.com](http://www.graceport.com) to chat with our customer service.