

PCB TERMINAL BLOCKS

5.08mm PCB Mounting Double Decker Terminal Blocks

- Space saving
- Double decker
- 4(2x2) and 6(2x3) pole interlocking
- Open ended modules
- Professional rising clamp terminals
- Guided pin alignment
- Available pre-assembled
- Polarised mouldings
-  approved

CTBDD93HJ



SPECIFICATION

Rating	20A/320V UL=12A/300V, VDE&IMQ=20A/320V
Dielectric strength	≥2.5kV
Impulse withstand voltage	4kV
Working temperature	110°C
Moulding	UL94-V0 flame retardant PA
Pin/terminal	Copper alloy, NI & SN


Vertical

5.08mm

TYPE NO.	POLES	LENGTH
CTBDD93VJ/2	4	12.7mm
CTBDD93VJ/3	6	17.8mm
CTBDD93VJ/4	8	22.9mm
CTBDD93VJ/5	10	27.9mm
CTBDD93VJ/6	12	33mm
CTBDD93VJ/7	14	38.1mm
CTBDD93VJ/8	16	43.2mm
CTBDD93VJ/9	18	48.3mm
CTBDD93VJ/10	20	53.3mm
CTBDD93VJ/11	22	58.4mm
CTBDD93VJ/12	24	63.5mm

5mm

TYPE NO.	POLES	LENGTH
CTBDD93VG/2	4	12.5mm
CTBDD93VG/3	6	17.5mm
CTBDD93VG/4	8	22.5mm
CTBDD93VG/5	10	27.5mm
CTBDD93VG/6	12	32.5mm
CTBDD93VG/7	14	37.5mm
CTBDD93VG/8	16	42.5mm
CTBDD93VG/9	18	47.5mm
CTBDD93VG/10	20	52.5mm
CTBDD93VG/11	22	57.5mm
CTBDD93VG/12	24	62.5mm

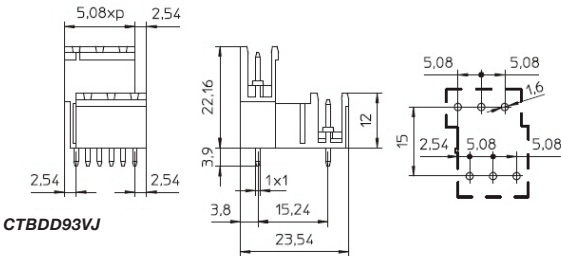


Horizontal

5.08mm

TYPE NO.	POLES	LENGTH
CTBDD93HJ/2	4	12.7mm
CTBDD93HJ/3	6	17.8mm
CTBDD93HJ/4	8	22.9mm
CTBDD93HJ/5	10	27.9mm
CTBDD93HJ/6	12	33mm
CTBDD93HJ/7	14	38.1mm
CTBDD93HJ/8	16	43.2mm
CTBDD93HJ/9	18	48.3mm
CTBDD93HJ/10	20	53.3mm
CTBDD93HJ/11	22	58.4mm
CTBDD93HJ/12	24	63.5mm

5mm

TYPE NO.	POLES	LENGTH
CTBDD93HG/2	4	12.5mm
CTBDD93HG/3	6	17.5mm
CTBDD93HG/4	8	22.5mm
CTBDD93HG/5	10	27.5mm
CTBDD93HG/6	12	32.5mm
CTBDD93HG/7	14	37.5mm
CTBDD93HG/8	16	42.5mm
CTBDD93HG/9	18	47.5mm
CTBDD93HG/10	20	52.5mm
CTBDD93HG/11	22	57.5mm
CTBDD93HG/12	24	62.5mm

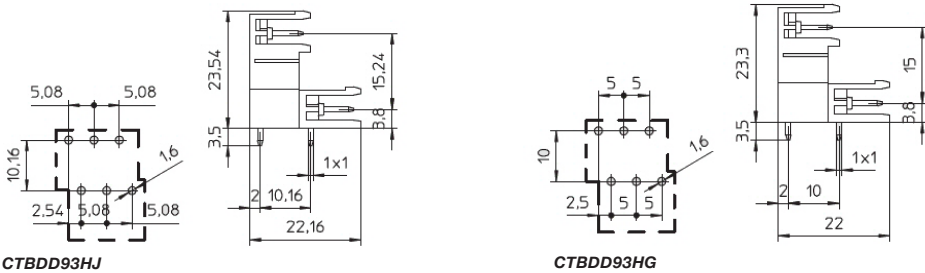

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS

RELAY
BASES

DIN RAIL
ENCLOSURES

BATTERIES

SOLAR
PANELS

TRANS-
FORMERS

