

CONSTANT VOLTAGE LED DRIVER

12VDC 20 WATT

POWERPAX: LED-DR-12V-1670-20W

Features:

- Input Voltage 200-240vac
- IP20 Rated
- Class II
- Compact Plastic Low Profile enclosure
- 1 Year Warranty



Description:

The Range of 20 watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP20 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications.

Specification	
Part Number	LED-DR-12V-1670-20W
Output Voltage Rating	12vdc
Output Current Range	1.67A
Rated Power	20 Watt
Dimensions	154 x 50 x 14mm
Input Voltage Range	200-240VAC
Input Voltage Frequency	50-60Hz
Inrush Current	<70A
Input power	<24.5W
Efficiency	≥ 82%
Power Consumption Without Load	<0.5W
Overload Protection	Ta ,0.94-1.06 times of input voltage, 1.4 times of rated power (auto recovery)
Short Circuit Protection	Ta ,0.94-1.06 times of input voltage (auto recovery)
Automatically Restart	Yes
Working Temperature	-20°C to +45°C
Relative Humidity	45% - 85%
MTBF	30k hours
EMC emission	EN55015
EMC Immunity	EN61547
Safety Standards	EN61347-1, EN61347-2-13


General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

CONSTANT VOLTAGE LED DRIVER 12VDC 20 WATT

POWERPAX: LED-DR-12V-1670-20W

Diagrams

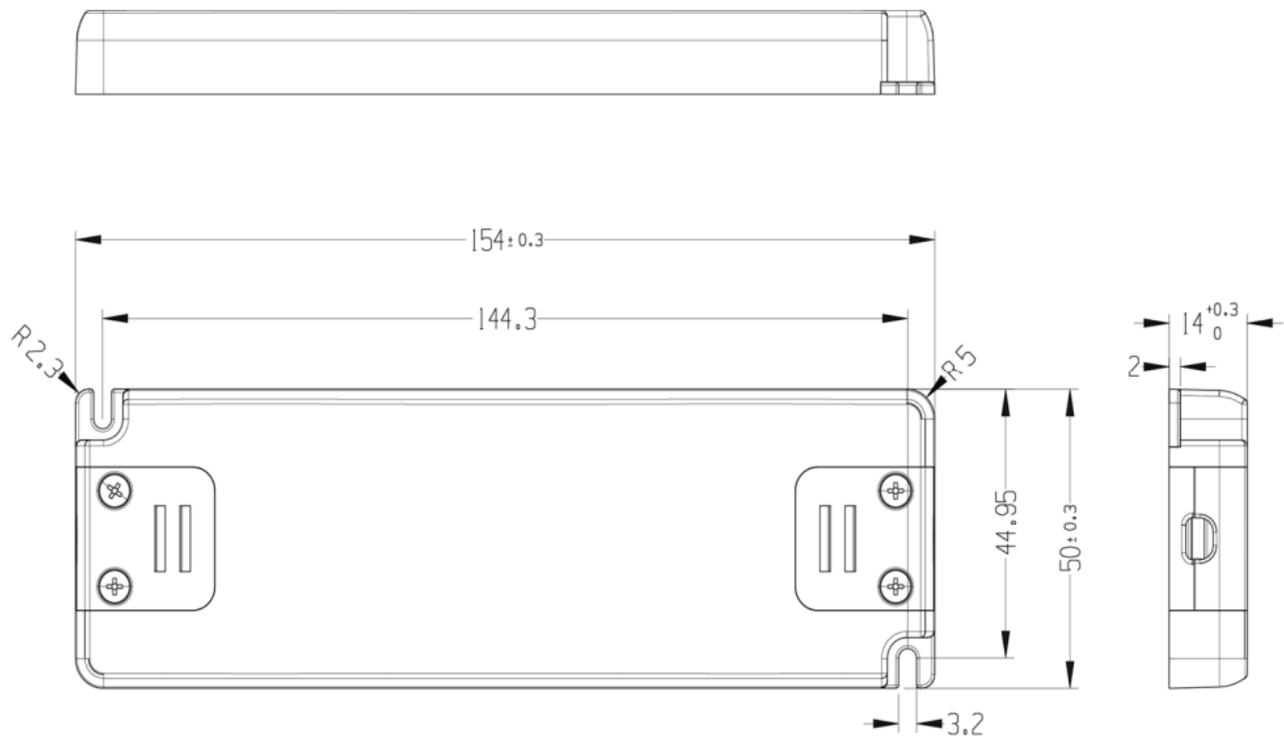

General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

POWERPAX