


12 WATT CONSTANT VOLTAGE LED DRIVER

POWERPAX: PAX1210TD

Features:

- Constant Voltage Output
- IP44 Rated
- Class II
- Compact Plastic Low Profile enclosure
- 2 Year Warranty

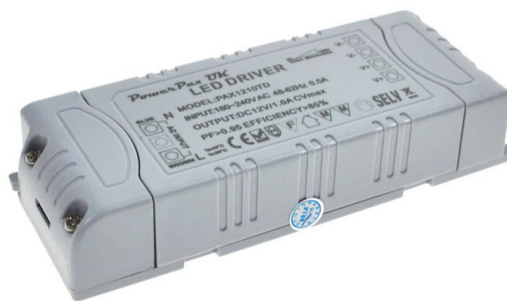

Description:

Range of 12 Watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP44 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications

Specification	
Part Number	PAX1210TD
Output Voltage	12Vdc
Output Current	1A
Rated Power	12 Watt
Dimensions	94 x 36 x 18mm
Power Factor	>0.95
Input Voltage Range	180V - 240VAC
Input Voltage Frequency	48 - 62Hz
Efficiency	>85%
Over Voltage Protection	110%-150% of rated OP
Operating Temperature	-25°C to +55°C
Safety	Design refers to EN60598 EN61547 ENV5024 EN61000-4-2,3,4,6,8,11 EN61000-3-2 EN61000-3-3
EMI	Meets emissions to EN55022, EN55015 Class B

POWERPAX

General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.