

60 WATT CONSTANT VOLTAGE LED DRIVER

POWERPAX: PAX1260TD-1

Features:

- Constant Voltage Output
- IP44 Rated
- Class II
- Compact Plastic Low Profile enclosure
- 2 Year Warranty



Description:

Range of 60 Watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP44 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications

Specification	
Part Number	PAX1260TD-1
Output Voltage Rating	12Vdc
Output Current	4A
Rated Power	60 Watt
Dimensions	170 x 50 x 31mm
Input Voltage Range	180-240VAC
Input Voltage Frequency	50-60Hz
Input Current	0.39A
Power Factor	>0.95
Efficiency	>80%
Short-circuit Protection	Auto-recovery
Over Current Protection	Auto-recovery
Over Voltage Protection	Auto-recovery
Operating Temperature	-30°C to +45°C
Storage Temperature	-40°C to +70°C
Relative Humidity	5% to 95% RH
Life Time	50K hours
EMI Standard	Meets Emissions to EN55022, EN55015 Class B
Safety Standard	Design refers to EN60598, EN61547, ENV5024, EN61000-4-2, 3, 4, 6, 8,11, EN61000-3-2, EN61000-3-3

POWERPAX

General Note



TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics IoT Solutions Ltd
Tofts Farm East, Brenda Road, Hartlepool, TS25 2BQ, UK
t: +44 (0) 1429 852 500

60 WATT CONSTANT VOLTAGE LED DRIVER

POWERPAX: PAX1260TD-1

Diagrams

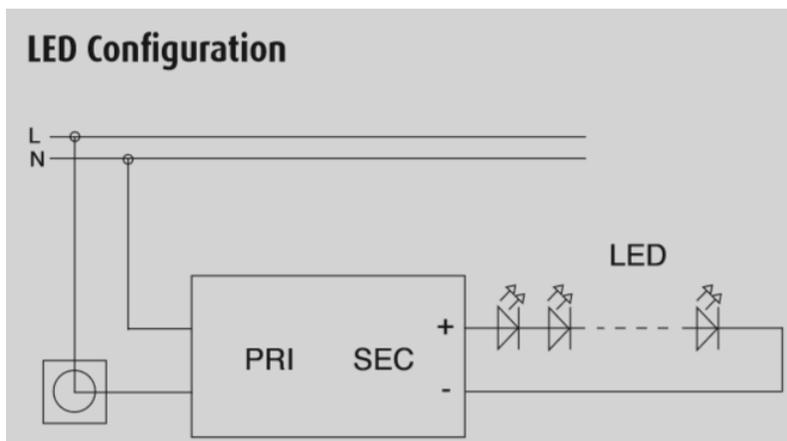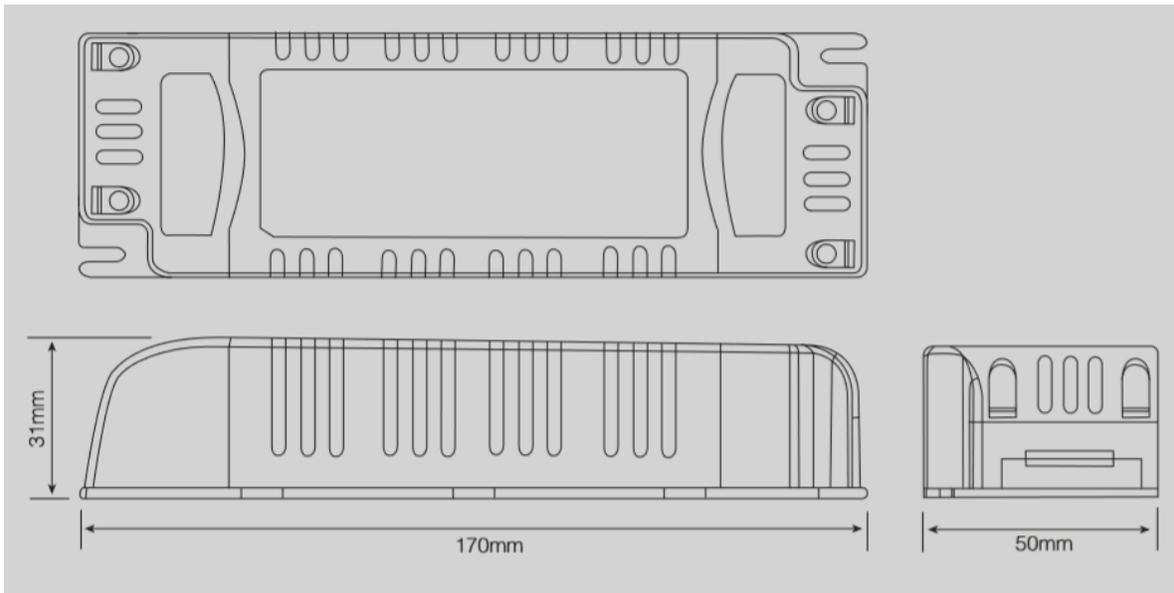

General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.