

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2180560220](#)  
**Status:** **Active**  
**Overview:** [EXTreme Guardian System](#)  
**Description:** EXTreme Guardian Female-to-EXTreme Guardian Female Off-the-Shelf (OTS) Cable Assembly, 11.00mm Pitch, Single Row, 2.0m Length, 2 Circuits, Black

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">218056</a>
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	EXTreme Guardian Both Ends
Overview	<a href="#">EXTreme Guardian System</a>
Product Name	EXTreme Guardian
Type	Discrete Wire Assembly
UPC	195842766006


**Physical**

Cable Length	2.0m
Circuits (Loaded)	2
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	PBT
Net Weight	450.000/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	11.00mm
Plating min - Mating	0.762µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Size AWG	6
Wire/Cable Type	UL 10669

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2180560205-000
---------------	----------------

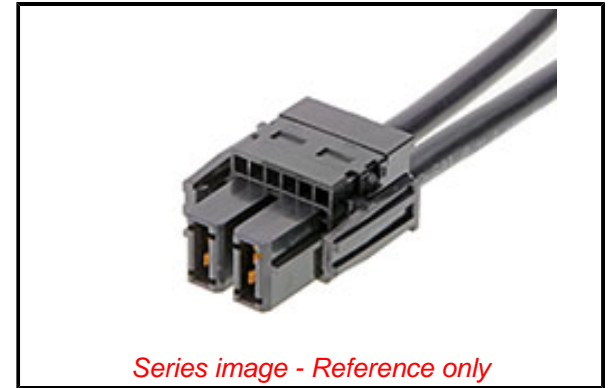

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[218056](#) Series

**Mates With**

[151035](#) EXTreme Guardian Power Right-Angle PCB Header, [151053](#) EXTreme Guardian Power Vertical PCB Header