

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2147205000](#)
Status: **Active**
Overview: [Zero-Hachi Connector System](#)
Description: Zero-Hachi Crimp Terminal, Female, Matte Tin (Sn) Plating, 28-30 AWG, Reel

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification 2147190000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification 2147209200-SPK-200 (PDF)	

General

Product Family	Crimp Terminals
Series	214720
Application	Signal, Wire-to-Board
Crimp Quality Equipment	Yes
Overview	Zero-Hachi Connector System
Product Name	Zero-Hachi
UPC	195842348523

Physical

Durability (mating cycles max)	20
Gender	Female
Material - Metal	Copper Alloy
Material - Plating Mating	Matte Tin
Net Weight	13.450/mg
Packaging Type	Reel
Plating min - Mating	1.000µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.50-0.60mm
Wire Size AWG	28, 30
Wire Size mm²	0.04-0.08


Electrical

Current - Maximum per Contact	1.0A
Voltage - Maximum	30V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Application Tooling Documents	2173623710ATS-000, 2173623710ATS-J-000
Packaging Specification	2147209200-SPK-200
Product Specification	2147190000-PS-000
Sales Drawing	2147200000-SD-000

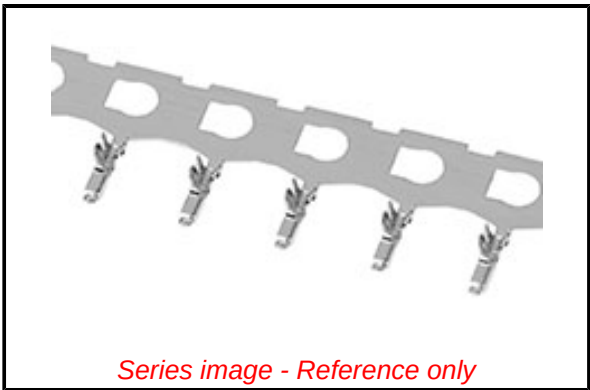

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)10043-DC (17
Jan 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[214720](#) Series

Use With

Zero-Hachi Receptacle Housing [214719](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION