

## OStream Long Distance Access Point (LDAP)

### Dimensions



### Specifications

**Power:** 110-240V Wall Plug

**Networking:**

To Camera:

- Point to Point Wireless Radios (Ripl)
- Spectrum: 2.4Ghz Spread Spectrum
- Distance: Up to 1KM
- Max Bandwidth: 2Mbps
- Support Cameras: Up to 10

To Internet:

- Ethernet, WiFi or Cellular (Optional)

**Enclosure:** IP67

**Dimensions:** w: 11cm h: 12.7cm d: 5cm

**Weight:** 300g

**Certifications:** FCC & CE


**CPU:** Rockchip RK3399 ARM

**OS:** Ubuntu 18LTS

**Updates:** OTA Through Cloud

## OStream Wirefree Object Camera

### Dimensions

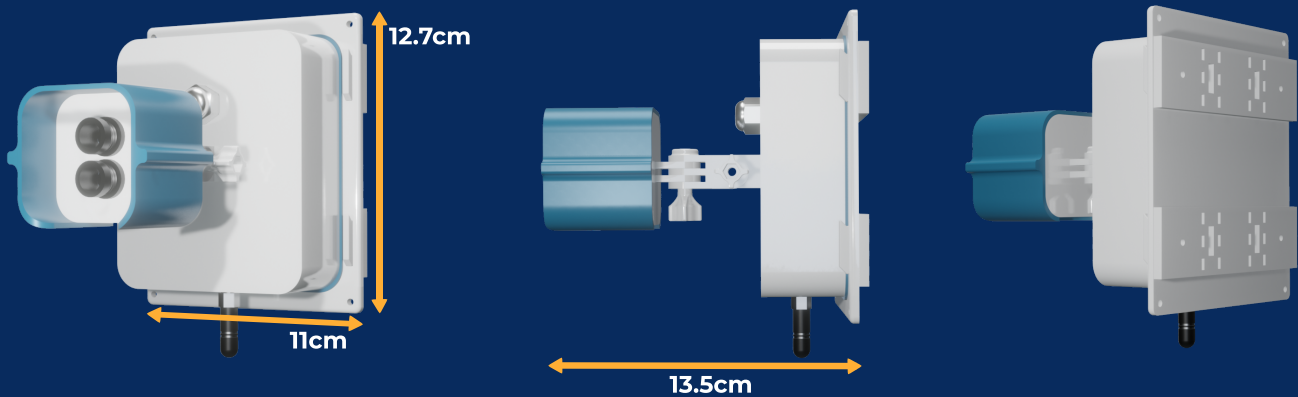

### Specifications

<b>Power:</b>	20,000 mAh
<b>Resolutions:</b>	5MP QVGA 320x240 up to QSXGA 2592x1944
<b>Motion Detect:</b>	Computer vision crops objects of interest
<b>Frames Per Sec:</b>	Up to 30; Per resolution and cropped objects
<b>Image Format:</b>	Jpeg
<b>Shutter:</b>	Rolling shutter / frame exposure
<b>Optical Size:</b>	1/4"
<b>Networking:</b>	<ul style="list-style-type: none"><li>- Point to Point Wireless Radios (RipI)</li><li>- Spectrum: 2.4Ghz Spread Spectrum</li><li>- Distance: Up to 1KM</li><li>- Max Bandwidth: 2Mbps</li></ul>
<b>Enclosure:</b>	IP67
<b>Dimensions:</b>	w: 11cm h: 12.7cm d: 13.5cm
<b>Weight:</b>	400g
<b>Certifications:</b>	FCC & CE
<b>CPU:</b>	STM32
<b>Updates:</b>	OTA Through LDAP