

ARCA 303021No MP

FIBOX
Enclosing innovations



Sample image

Order symbol: ARCA 303021No MP

Product nbr: 8120005N

Description: Cabinet. PC


Remarks: Grey cover. 2-point locking.

EAN: 6418074086631

El. number:


- Finland:
- Denmark:
- Sweden: 2506466

Including: Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

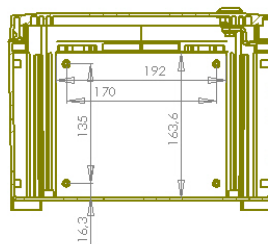

ARCA IEC DRS

ARCA IEC IDS

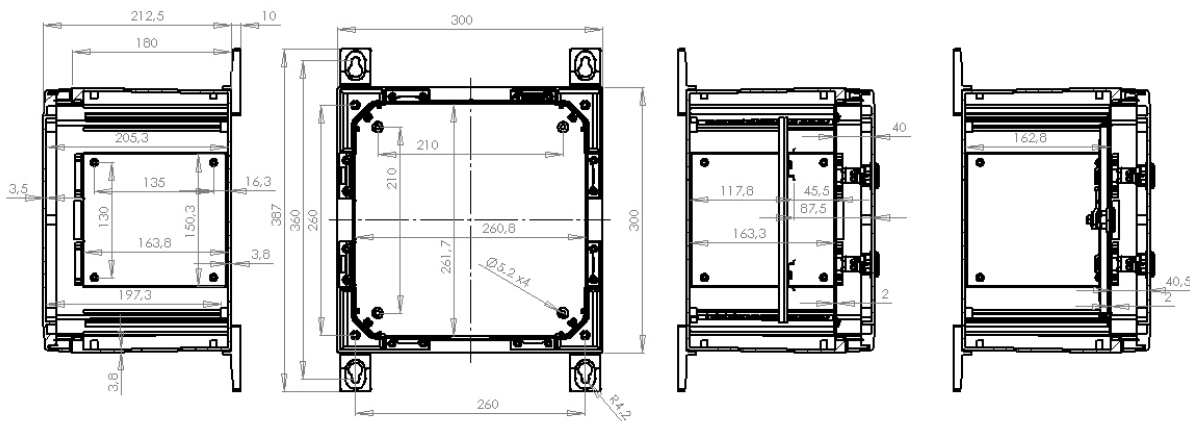

Dimensions:	Height	Width	Depth
mm:	300	300	210
inch:	11.81	11.81	8.58

Materials:	
Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:		
Temperature °C (short term)::	-40 ... 120	
Temperature °C (continuous):	-40 ... 80	
Temperature °F (short term):	-40 ... 250	
Temperature °F (continuous):	-40 ... 175	

Accessories:	
MPX ARCA 3030	Mounting plate (250x250 mm) (250 x 250 x 5)
MPMP ARCA 3030	Mounting plate multiperforated (250x250x2 mm - ø3.6 mm) (250 x 250 x 2)
MPS ARCA 3030	Mounting plate (250x250x2 mm) (250 x 250 x 2)
IDS ARCA 3030	Inner door set (280 x 280 x 30)
MPP ARCA 3030	Mounting plate perforated (250x250x2 mm - 26x11 mm) (250 x 250 x 2)
DRS ARCA 303021	DIN rail frame set (285 x 285 x35)

Rating:	
Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

Certificates:	
Certificate FI 40467	