


Kunststoff Bügelgriffe

Plastic Bow-Type Handles

Technische Daten

Werkstoff Duroplast Typ FS 31 schwarz, Gewindeeinsatz St
Belastbarkeit 500 N

Dieser Bügelgriff für Geräte und Einschübe aus hochbelastbarem und hitzebeständigem Kunststoff ist vielseitig einsetzbar.

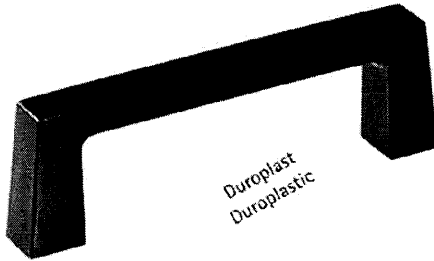


Art.-Nr. 267.13

Technical Data

Material Duroplastic Type FS 31 black, threaded insert steel
Carrying capacity 500 N

This bow-type handle for devices and racks is made from highly durable and heat-resistant plastic and is versatile in its use.

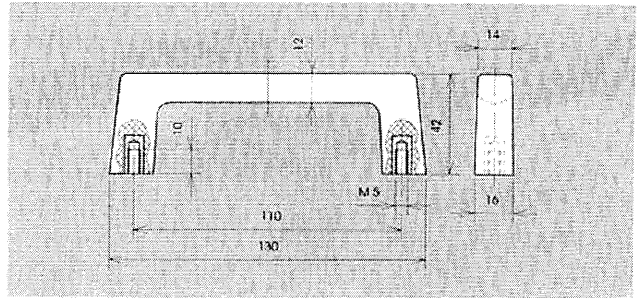

Einschließlich Schrauben DIN 84-M5 x 12 und Scheiben DIN 125.
Including screws DIN 84-M5 x 12 and washers DIN 125.

Technische Daten

Werkstoff ABS schwarz, Blende Aluminium
Belastbarkeit 400 N


Bügelgriff mit eingesetzter Blende. Er eignet sich für Zug- und Schubtätigkeit. Die Blende ist verfügbar in naturton eloxiert und schwarz eloxiert und muss separat bestellt werden.



Technical Data

Material ABS black, screen aluminium
Carrying capacity 400 N

Bow-type handle with panel insert. It is suitable for pulling and pushing actions. The screen is available in anodized natural or black color. The screen must be ordered separately.

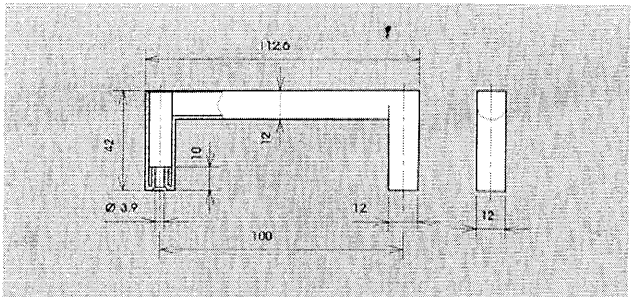

Einschließlich Schrauben DIN 84-M3,5 x 20, Scheiben DIN 125 und Muttern DIN 934-M3,5.
Including screws DIN 84-M3,5 x 20, washers DIN 125 and nuts DIN 934-M3,5.

Ausführung - Design	Art.-Nr.
Griff ohne Blende Handle without screen	3315.1003
Blende naturton eloxiert screen natural anodized	3315.0011
Blende schwarz eloxiert screen black anodized	3315.0031