

PRODUCTS



[Products](#) > [Product Type](#) > [Datacom](#) > [Connectors](#) > [Modular Plugs](#) >

CHAMPIONS CLUB

RJ-11(RJ-12) 6P6C Modular Plugs -25 pk

RJ-11(RJ-12) 6P6C MODULAR PLUGS -25 PK



IDEAL NATIONALS

LEARN

ABOUT

SKU 85-345


WHERE TO BUY

[**ADD TO COMPARE**](#)

RJ-11(RJ-12) 6P6C Modular Plugs -25 pk

[Be the first to review this product](#)



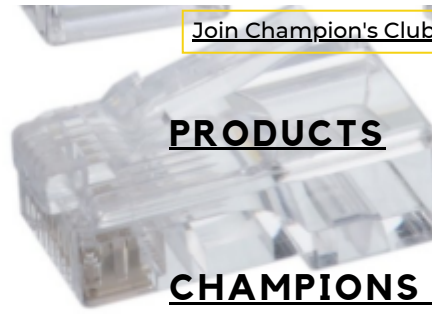

PRODUCTS



CHAMPIONS CLUB



IDEAL NATIONALS

LEARN

ABOUT

Details

- 6 position, 6 contact RJ-11 modular plug for Cat 3/5e and traditional phone wire
- 50 micro-inch gold plating on contact mating area for long term reliability in connectivity, even after hundreds of mating cycles
- Complies with industry standard mechanical and electrical specifications for compatibility with compliant telephone jacks and ports
- Designed to work seamlessly with IDEAL Telemaster™ crimping tools. Also compatible with industry standard modular plug crimping tools meeting specifications.
- Use with 1, 2, or 3 line phone systems

The six position RJ-11 style modular plug is traditionally used in voice/phone applications. Two versions are available: 6P6C (six position/six contact) and 6P4C (six position/four contact). The RJ-11 6P4C (four contacts) is used for 1 or 2 line phone systems common in residential systems. The RJ-12 6P6C (six contacts) is used for 1, 2, or 3 line systems and is found in more commercial systems. Modular plug connectors support the latest TIA/EIA standards for twisted pair cabling. IDEAL modular plugs are designed to work seamlessly with the IDEAL Telemaster™ series of modular plug crimp tools. Plugs are designed and manufactured to support all 100Ω cable wiring schemes.

IDEAL® modular plugs are manufactured to strict industry standards and tolerances that utilize traditional preparation and termination methods. These proven and preferred methods allow for improved compatibility among manufacturers and devices around the world without the need for special tooling or preparation methods, and eliminate the risk of shorts and crosstalk often associated with open end or feed through type connectors.

[PRODUCTS](#)



[CHAMPIONS CLUB](#)

6 position, 6 contact RJ-11 modular plug for Cat 3/5e and traditional phone wire with 18 inch gold plating on contact mating area for superior connectivity, even after hundreds of mating cycles

[IDEAL NATIONALS](#)

Complies with industry standard mechanical and electrical specifications for compatibility with compliant telephone jacks and ports

[LEARN](#)

Designed to work seamlessly with IDEAL Telemaster™ crimping tools. Also compatible with industry standard modular plug crimping tools meeting specifications.

[ABOUT](#)

Use with 1, 2, or 3 line phone systems • Three prong contact design for use with solid or stranded 24-26 AWG insulated copper conductors

Permanent connection - once crimped they cannot be reused

Primary strain relief supports to retain cable jacket and minimize conductor movement once crimped

Non feed through design to prevent external conductor/device shorting and RF signal leakage

[More Information](#)

[Reviews](#)

Related Products



[RJ-11 to RJ-45 Modular](#)

[Plugs - 25 pk](#)
[Compare](#)



[Prep. RJ-45 Cat 5e UTP](#)

[Cable Stripper](#)

[Compare](#)

[Electrician's Snissors](#) [Champion's Club](#) [Careers](#) [Contact Us](#)

[Compare](#)

[PRODUCTS](#)



[CHAMPIONS CLUB](#)

[IDEAL NATIONALS](#)

[LEARN](#)

[ABOUT](#)



[#IDEALelectrical](#)

[Privacy Policy](#) [Legal Notice](#) [MAP Policy](#) [Terms of Use](#)

[Terms of Sale](#) [CA Transparency Notice in Supply Chain Act Disclosure](#) [Slavery Human Trafficking Statement](#) [Supplier Code of Conduct](#)

[Apparel and Merchandise](#) [Product Registration](#) [RMA Registration](#) [IDEAL National Championship Official Rules](#)

[SMS Terms and Conditions](#)



[IDEAL Full Line Catalog.Pdf](#)

(170 MB)

