 


NEBO®

12K



12K

The 12K features a high-power C-O-B, 12,000 lumen Turbo mode, Smart Power Control, USB power bank and a power indicator.

MODES	LUMENS	HOURS	METERS
TURBO	12000	40 sec.	220
HIGH	7000	2	164
MEDIUM	3000	3	114
LOW	300	12	36
STROBE	3000	2	114

5 Light Modes • Waterproof (IP67) • USB Rechargeable
Smart Temperature Control • USB Power Bank • Direct-to-Low
Smart Power Control • Anodized Aircraft-Grade Aluminum

OPERATION

Press button to activate and cycle through light modes: **High > Medium > Low > Off**
When light is ON for 8 seconds or longer, the next button press will turn light OFF.

Strobe: Double-tap button

Turbo: From ON, press and hold button


Direct-to-Low: From OFF, press and hold button

Smart Power Control (SPC) seamlessly transitions through light modes



2X ZOOM

Twist to adjust light beam from flood light to spot light.

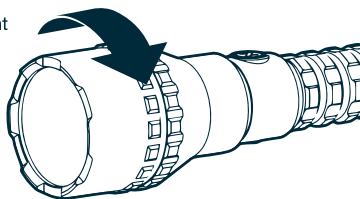

RECHARGEABLE


Use the included charging cable to recharge the 12K. Power button will indicate battery level.

POWER INDICATOR

Steady Orange: Battery more than 25%
Flashing Orange: Battery less than 25%

CHARGING INDICATOR

Pulsing Green: Battery charging
Steady Green: Battery fully charged

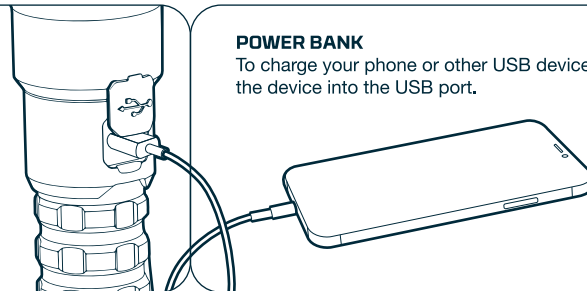

POWER BANK

To charge your phone or other USB device, simply plug the device into the USB port.

This product is guaranteed against all defects in workmanship and materials for the original owner for one year from the date of purchase.



For more information, detailed video instructions, and warranty registration, visit NEBOLIGHTS.com.