

Product information

25 05 140

Snipe Nose Side Cutting Pliers (Radio Pliers)

DIN ISO 5745

- Suitable for finer gripping and cutting work
- Half-round, long, tapered jaws
- Knurled gripping surfaces
- With cutting edges for soft, medium-hard and hard wire
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 61 HRC
- Straight jaws
- Vanadium electric steel, forged, multi stage oil-hardened




General

Article No.	25 05 140
EAN	4003773035015
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	111 g
Dimensions	140 x 55 x 17 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Cutting capacities medium hard wire (diameter)	Ø 2.5 mm
Cutting capacities hard wire (diameter)	Ø 1.6 mm
Jaw thickness (joint) (T1)	8.0 mm
Tips width (W4)	2.5 mm
Tips thickness (T2)	2.0 mm
Jaw length (L3)	42.0 mm
Head width (W3)	15 mm

Technical details

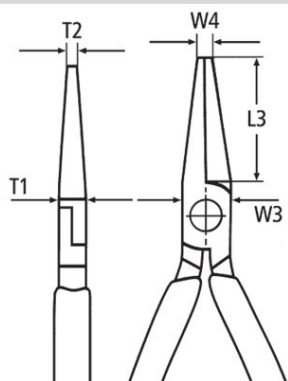

Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted