

## Product information

# 29 11 160

- Gripping surfaces cross-hatched, knurled
- Flat, wide jaws
- Chrome vanadium electric steel, forged, oil-hardened

## Telephone Pliers

DIN ISO 5745




### General

Article No.	29 11 160
EAN	4003773016175
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	103 g
Dimensions	160 x 53 x 15 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

### Technical details

Jaw thickness (joint) (T1)	8.0 mm
Tips width (W4)	2.5 mm
Tips thickness (T2)	8.5 mm
Jaw length (L3)	55.0 mm
Head width (W3)	14.0 mm

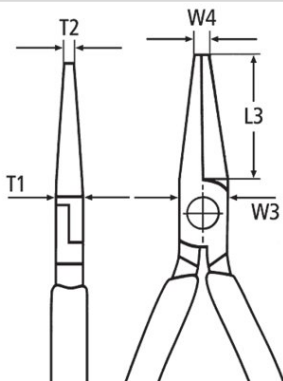



<b>Classification</b>	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	EAC010c041
UNSPSC 13.1	27112134

*technical change and errors excepted*