

Product information

30 11 140

Long Nose Pliers

DIN ISO 5745

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Knurled gripping surfaces
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	30 11 140
EAN	4003773033936
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	86 g
Dimensions	140 x 51 x 12 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	8.0 mm
Tips width (W4)	2.5 mm
Tips thickness (T2)	4.0 mm
Jaw length (L3)	42.0 mm
Head width (W3)	15.0 mm

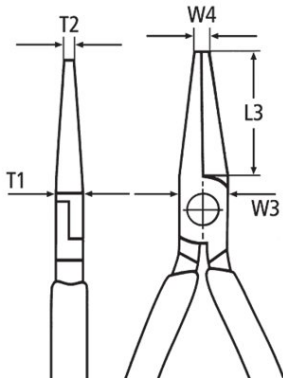



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted