

Product information

30 25 190

Long Nose Pliers

DIN ISO 5745

- Heavy duty and wear resisting
- Different jaw styles
- Long, half-round jaws
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	30 25 190
EAN	4003773043515
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	168 g
Dimensions	190 x 56 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	8.0 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.4 mm
Jaw length (L3)	50.0 mm
Head width (W3)	18.5 mm

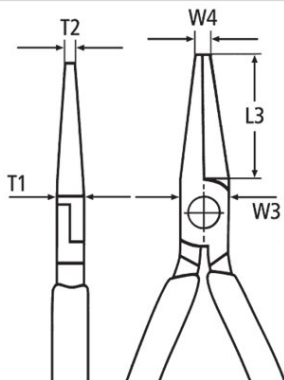

Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted