

Product information

38 41 190

- High bending strength of the pliers tips
- Flat, wide jaws
- Vanadium electric steel; forged, oil-hardened

Mechanics' Pliers

DIN ISO 5745




General

Article No.	38 41 190
EAN	4003773017141
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	139 g
Dimensions	190 x 53 x 11 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	8.0 mm
Tips width (W4)	4.0 mm
Tips thickness (T2)	8.0 mm
Jaw length (L3)	50.0 mm
Head width (W3)	18.0 mm

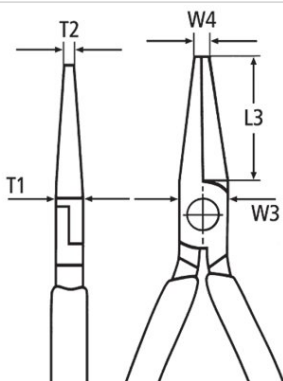



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted