

 
Product information

38 71 200


- High bending strength of the pliers tips
- 70° angled, half-round jaws, suitable for pulling split pins; for gripping at points that are difficult to access
- Vanadium electric steel; forged, oil-hardened

Mechanics' Pliers

DIN ISO 5745



General	
Article No.	38 71 200
EAN	4003773017202
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	174 g
Dimensions	200 x 53 x 13 mm
Standard	DIN ISO 5745
Reach	no
RohS	no
Technical details	
Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.0 mm
Jaw length (L3)	73.0 mm
Head width (W3)	17.5 mm
Head angle	70 °

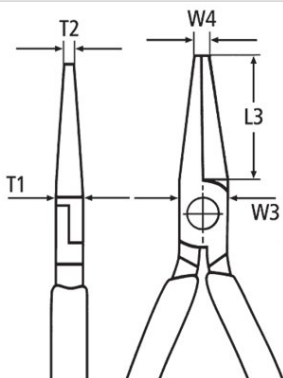

Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted

