

## Product information

# 78 61 140 ESD

## Electronic Super Knips® XL ESD

DIN ISO 9654 DIN EN 61 340-5



**High leverage, sharp cutting edges:** Precise cutting of wires from Ø 0.2 mm and cable ties


- Additional 15 mm longer version: greater stability, greater cutting performance
- High load capacity, made of burnished special tool steel, cutting edges additionally induction-hardened to 64 HRC
- Precision-ground cutting edges without bevel for precise and flush cutting of the finest wires, e.g. in electronics and fine mechanics
- Precisely shaped tips cut wires close to a surface from Ø 0.2 mm
- With opening spring and opening limiter for comfortable, ergonomic and fast working thanks to automatic opening and comfortable handle width
- Extremely easy movement for fatigue-free work due to precise joint with stainless steel rivet
- Special tool steel, oil hardened in multiple stages

### General

Article No.	78 61 140 ESD
EAN	4003773081708
Pliers	burnished
Head	burnished
Handles	with multi-component grips
Weight	85 g
Dimensions	140 x 83 x 14 mm
Standard	DIN ISO 9654 DIN EN 61 340-5
Reach	no
RohS	no

### Technical details

Cutting capacities medium hard wire (diameter)	Ø 1.4 mm
Cutting capacities soft wire (diameter)	Ø 0.2 – 2.1 mm
Jaw length (B)	12.3 mm
Jaw thickness (joint) (D)	9.2 mm
Head width (A)	15.7 mm
ESD	yes

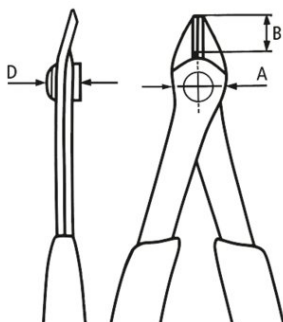

Classification	
eCl@ss 5.1.4	21040302
ETIM 5.0	EC000165
ETIM 6.0	EC000165
proficl@ss 6.0	AAA949c004
UNSPSC 13.1	27112149

*technical change and errors excepted*

