

# NEO ABS 322215 G



Sample image

**Order symbol:** NEO ABS 322215 G

**EAN:** 6418074311436

**Product nbr:** 4812000


**El. number:**

**Description:** Hinged ABS enclosure with grey cover

- Finland: 3424417
- Denmark: 8212098080
- Sweden: 2506221

**Remarks:**

**Including:** ABS base and cover, mounting screws for mountingplate/DIN rail.

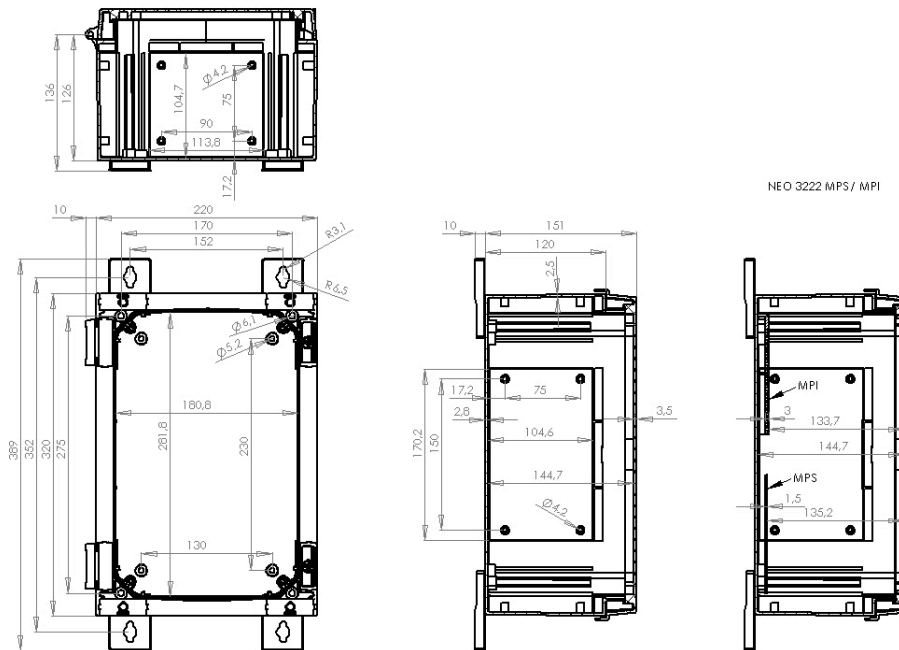

**Dimensions:**

|       | Height | Width | Depth |
|-------|--------|-------|-------|
| mm:   | 320    | 220   | 150   |
| inch: | 12.6   | 8.66  | 5.91  |

**Accessories:**

|              |  |
|--------------|--|
| NEO MPI 3222 | Multiperforated plastic mounting plate (275 x 165 x 3) |
| NEO MPS 3222 | Metal mounting plate (275 x 165 x 1.5)                 |

**Materials:**

|                  |                      |
|------------------|----------------------|
| Material:        | ABS                  |
| Base colour:     | RAL 7035 -light grey |
| Cover colour:    | RAL 7035 -light grey |
| Gasket material: | Polyurethane         |

|                 |   |
|-----------------|---|
| PMK NEO 20      | Pole mounting kit<br>(300 x 200 x 30)       |
| WMK NEO plastic | Wall mounting kit plastic<br>(80 x 70 x 40) |

**Temperatures:**

|                               |             |
|-------------------------------|-------------|
| Temperature °C (short term):: | -40 ... 80  |
| Temperature °C (continuous):  | -40 ... 60  |
| Temperature °F (short term):  | -40 ... 175 |
| Temperature °F (continuous):  | -40 ... 140 |

**Rating:**

|  |                   |
|--|-------------------|
| Ingress protection (EN 60529):         | IP66; IP67;       |
| Impact Resistance (EN 62262):          | IK08;             |
| Electrical insulation:                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815): | 1                 |
| UV resistance:                         | -                 |
| Flammability Rating:                   | UL 94 HB          |
| Glow Wire Test (IEC 695-2-1) °C:       | 650 °C            |
| NEMA Class                             |                   |

**Certificates:**

Certificate FI 40693 A1.pdf