

NEO ABS 423215 G

FIBOX
Enclosing innovations



Sample image

Order symbol: NEO ABS 423215 G

EAN: 6418074311450

Product nbr: 4812002


El. number:

Description: Hinged ABS enclosure with grey cover

- Finland: 3424419
- Denmark: 8212098103
- Sweden: 2506223

Remarks:

Including: ABS base and cover, mounting screws for mountingplate/DIN rail.

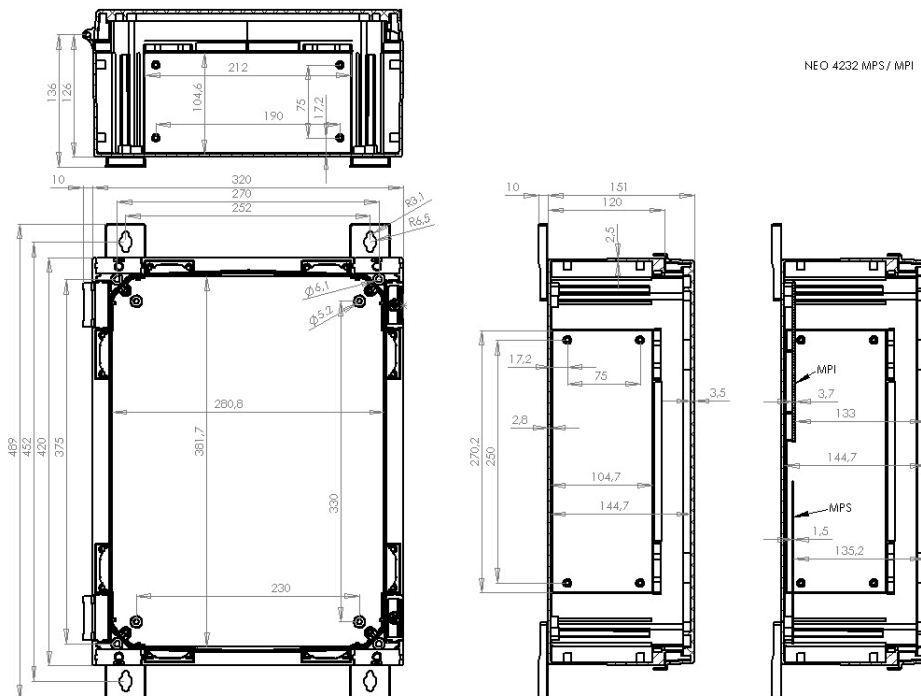

Dimensions:

	Height	Width	Depth
mm:	420	320	150
inch:	16.54	12.6	5.91

Accessories:

NEO MPI 4232	Multiperforated plastic mounting plate (375 x 265 x 3)
NEO MPS 4232	Metal mounting plate (375 x 265 x 1.5)

Materials:

Material:	ABS
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

PMK NEO 30	Pole mounting kit (400 x 300 x 30)
WMK NEO plastic	Wall mounting kit plastic (80 x 70 x 40)

Temperatures:

Temperature °C (short term)::	-40 ... 80
Temperature °C (continuous):	-40 ... 60
Temperature °F (short term):	-40 ... 175
Temperature °F (continuous):	-40 ... 140

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C:	650 °C
NEMA Class	

Certificates:

Certificate FI 40693 A1.pdf