

NEO PC 323215 T



Sample image

Order symbol: NEO PC 323215 T

Product nbr: 4811001

Description: Hinged polycarbonate enclosure with transparent cover


Remarks:

EAN: 6418074311399

El. number:

- Finland: 3424413
- Denmark: 8212098064
- Sweden: 2506219

Including: Polycarbonate base and cover, mounting screws for mountingplate/DIN rail.

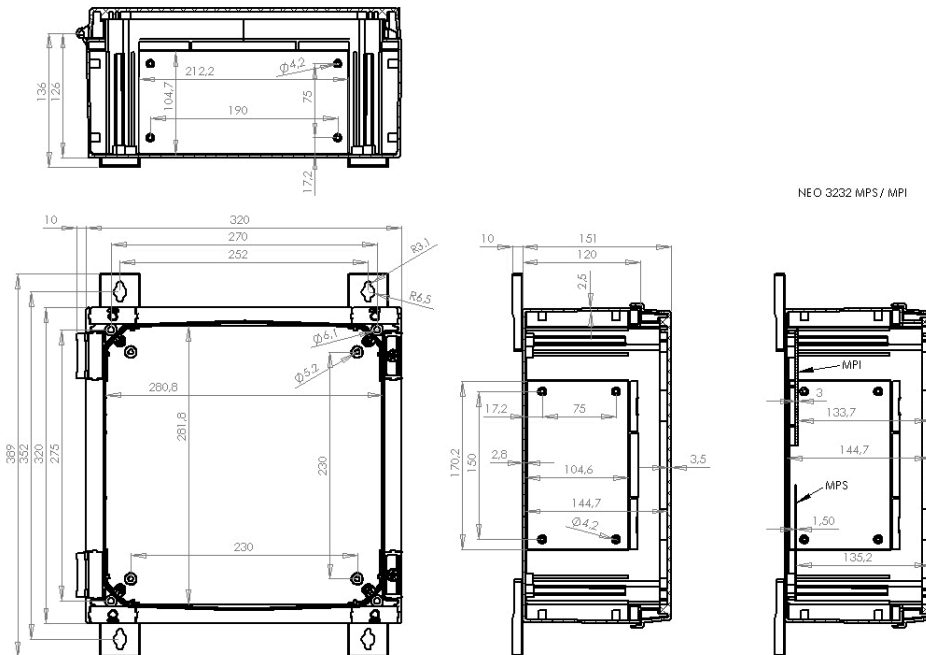

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm: | 320 | 320 | 150 |
| inch: | 12.6 | 12.6 | 5.91 |

| Accessories: | |
|--------------|--|
| NEO MPI 3232 | Multiperforated plastic mounting plate (275 x 265 x 3) |
| NEO MPS 3232 | Metal mounting plate (275 x 265 x 1.5) |

Materials:

| | |
|------------------|----------------------|
| Material: | Polycarbonate |
| Base colour: | RAL 7035 -light grey |
| Cover colour: | Clear transparent |
| Gasket material: | Polyurethane |

Temperatures:

| | |
|-------------------------------|-------------|
| Temperature °C (short term):: | -40 ... 120 |
| Temperature °C (continuous): | -40 ... 80 |
| Temperature °F (short term): | -40 ... 250 |
| Temperature °F (continuous): | -40 ... 175 |

| | |
|-----------------|---|
| PMK NEO 30 | Pole mounting kit (400 x 300 x 30) |
| WMK NEO plastic | Wall mounting kit plastic (80 x 70 x 40) |

Rating:

| | |
|--|-------------------|
| Ingress protection (EN 60529): | IP66; IP67; |
| Impact Resistance (EN 62262): | IK09; |
| Electrical insulation: | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815): | 1 |
| UV resistance: | UL 508 |
| Flammability Rating: | UL 94 5VA |
| Glow Wire Test (IEC 695-2-1) °C: | 960 °C |
| NEMA Class | |

Certificates:

Certificate FI 40693 A1.pdf