

Data sheet Illuminated pushbutton Ø 19 mm silver contact.


Part No.: 82-5552.1124

Technical data




| | |
|-----------------------|--|
| Terminal | Screw terminal |
| Shape of illumination | Ring |
| Operating voltage | 24 V DC |
| Operating Travel | ca. 3 mm |
| Lens illumination | illuminative |
| Lens colour | Nature |
| Lens shape | flush |
| Lens material | Aluminium |
| Lens surface | anodised |
| Lens optics | opaque |
| Front bezel shape | flush |
| Front bezel material | Aluminium |
| Weight | 0.018 kg |
| Contact material | Silver |
| Illumination colour | Blue |
| Kind of illumination | Single-LED |
| Switching action | Momentary |
| Switching system | Snap-action switching element |
| Contacts | 1 FS |
| Operating temperature | - 30 °C ... + 70 °C |
| Approbations | CB, CCC, C UL, UL |
| Operating force | 4 ... 7 N |
| Climate resistance | Damp heat, 21 days according to IEC 60512-11 |

Dimensions

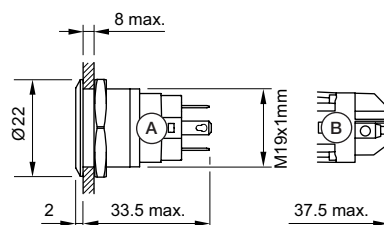

A = Solder terminal
B = Screw terminal

Mounting cut-outs

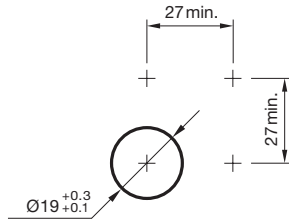

Wiring diagrams



Component layouts

