

ABS 2819 13 G



Sample image

Order symbol: ABS 2819 13 G

Product nbr: 5880360

Description: Enclosure. ABS



Remarks: Opaque cover

Including: Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

EAN: 6418074039026

El. number:

- Finland: 3423755
- Denmark:
- Sweden: 2539709

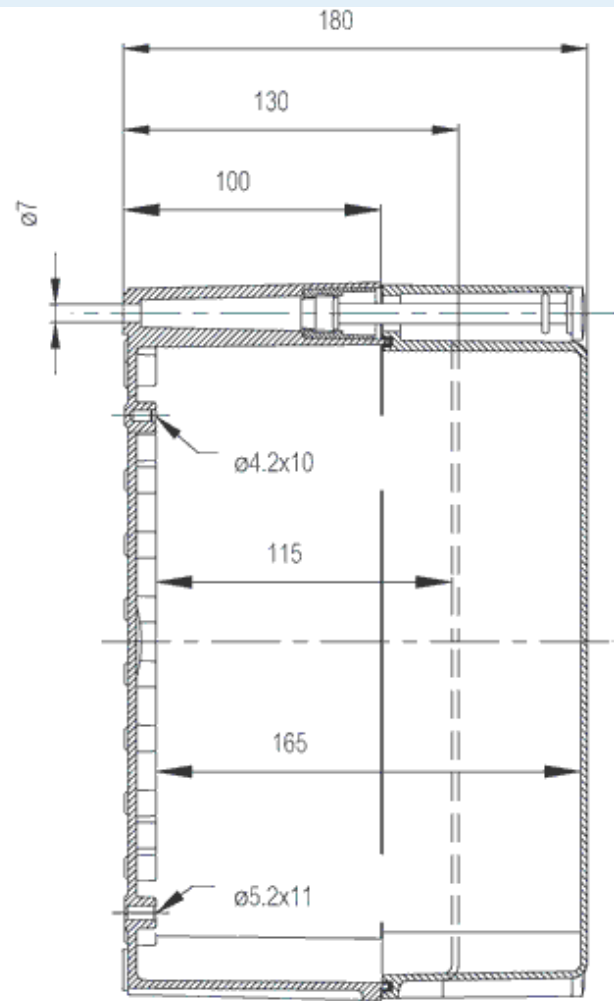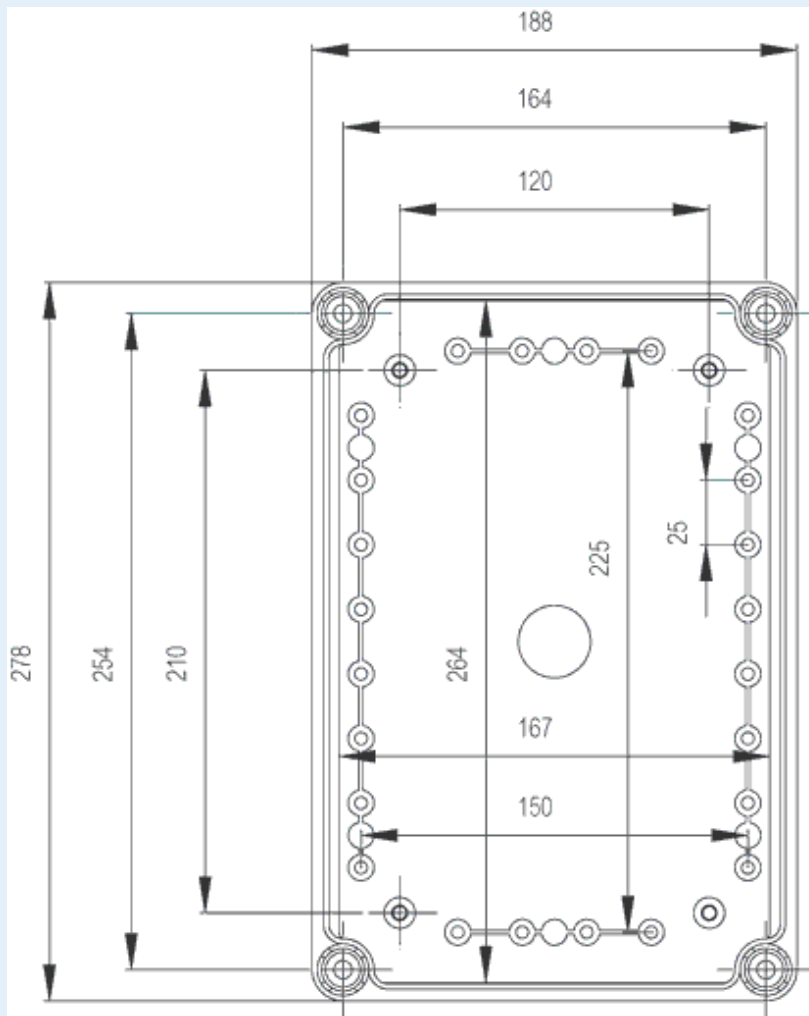

Dimensions:	Height	Width	Depth
mm:	280	190	130
inch:	11.02	7.48	5.12

Materials:

Material:	ABS
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term)::	-40 ... 80
Temperature °C (continuous):	-40 ... 60
Temperature °F (short term):	-40 ... 175
Temperature °F (continuous):	-40 ... 140

Accessories:

EKV 12	DIN-35 Mounting rail. for enclosures: (160 x 35 x 1)
EKJVT	Back Panel. for enclosures: (238 x 148 x 1)
EKV 22	DIN-35 Mounting rail. for enclosures: (235 x 35 x 1)
EKJZR	Extension frame. for enclosures: (280 x 190 x 50)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C:	650 °C
NEMA Class	

Certificates:

Certificate NCS FI 30308

