

# CAB PCQ 403017 T



Sample image

**Order symbol:** CAB PCQ 403017 T

**Product nbr:** 8113058

UL Code: 8143058

UL Name: UL CAB PCQ 403017 T

**Description:** Enclosure. PC


**Remarks:** Smoked transparent cover

**EAN:** 6418074011091

**El. number:**

- Finland: 3421924
- Denmark:
- Sweden: 2539192

**Including:** Base with screws for mounting plate/DIN-rail. internal corner plugs. cover with PUR gasket and CS 12137 cover screws.

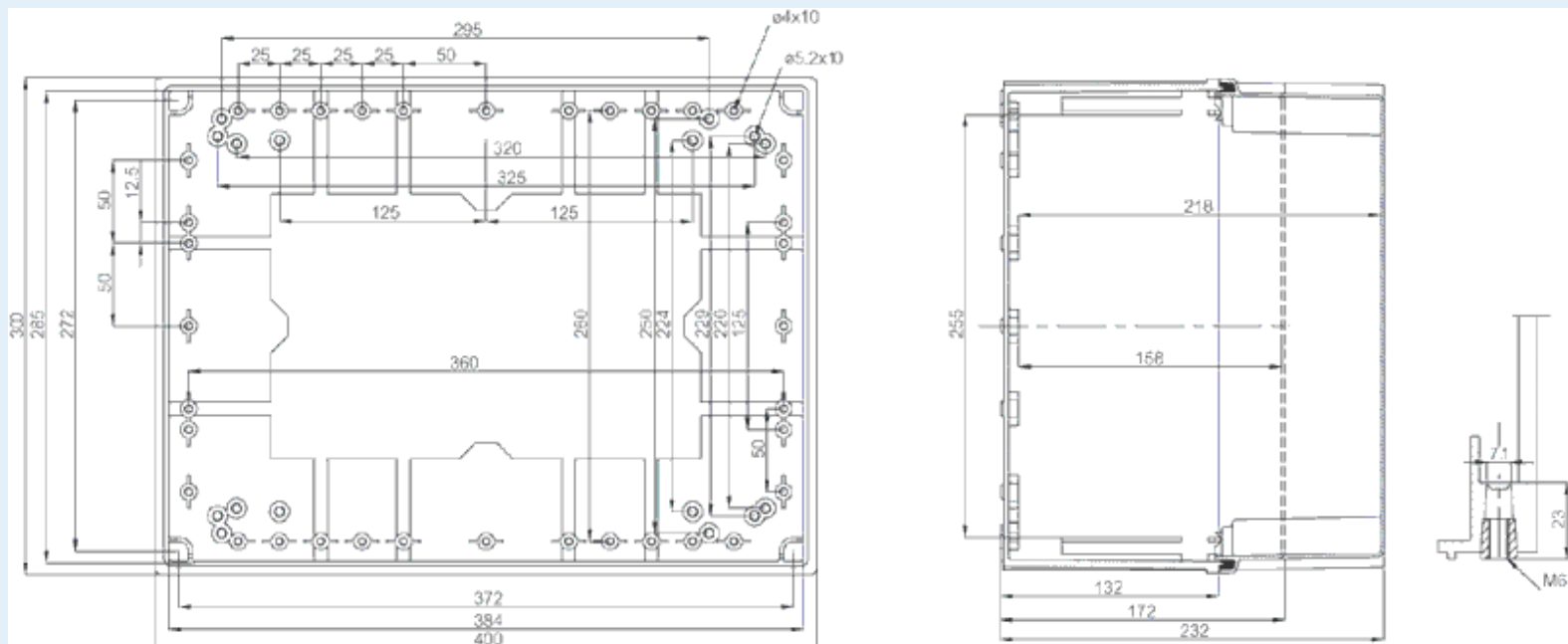

Dimensions:	Height	Width	Depth
mm:	400	300	170
inch:	15.75	11.81	6.69

**Materials:**

**Accessories:**

DRF 43/44 DIN rail frame kit. for enclosures:

PAT 12040 Hinge kit

MB 12225 AL Swing door kit

EKIV 37 DIN-35 Mounting rail. for enclosures:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

	(366 x 35 x 1)
EKIV 27	DIN-35 Mounting rail. for enclosures: (266 x 35 x 1)
EKIV 43	Back Panel. for enclosures: (370 x 270 x 1)
FP A 43	Swing-out door/Front panel (aluminum). for enclosures: (268 x 368 x 1)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

Certificate FI 40848