

MPMP ARCA 6040

FIBOX
Enclosing innovations



Sample image

Order symbol: MPMP ARCA 6040

Product nbr: 8120925

Description: Mounting plate multiperforated (550x350x2 mm - $\varnothing 3.6$ mm)


Remarks: Galvanized steel. for size 600x400x210

EAN: 6418074089526

Including:

El. number:

- Finland:
- Denmark:
- Sweden:

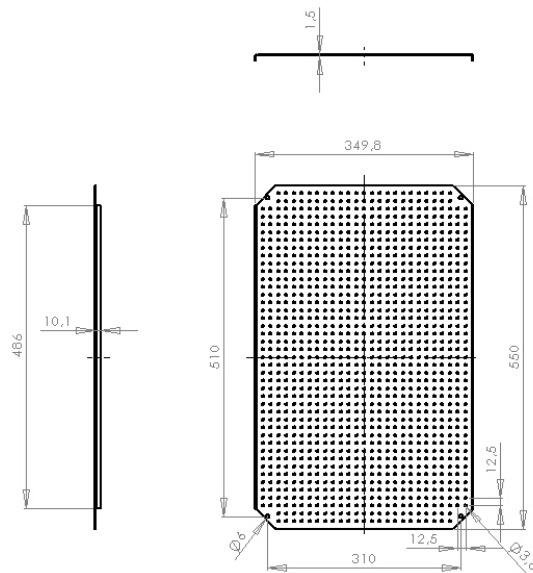

Dimensions:	Height	Width	Depth
mm:	550	450	2
inch:	0	0	0.08

Materials:
Material:
Base colour:
Cover colour:
Gasket material:

Temperatures:
Temperature °C (short term)::
Temperature °C (continuous):
Temperature °F (short term):
Temperature °F (continuous):

Rating:	
Ingress protection (EN 60529):	
Impact Resistance (EN 62262):	
Electrical insulation:	Not insulated
Halogen free (DIN/VDE 0472, Part 815):	0
UV resistance:	-
Flammability Rating:	
Glow Wire Test (IEC 695-2-1) °C:	C
NEMA Class	

Certificates:
