

# PC 121614



Sample image

**Order symbol:** PC 121614

**Product nbr:** 7032730

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**EAN:** 6418074058416

**El. number:**

- Finland: 3435362
- Denmark: 8212002827
- Sweden: 2536124

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

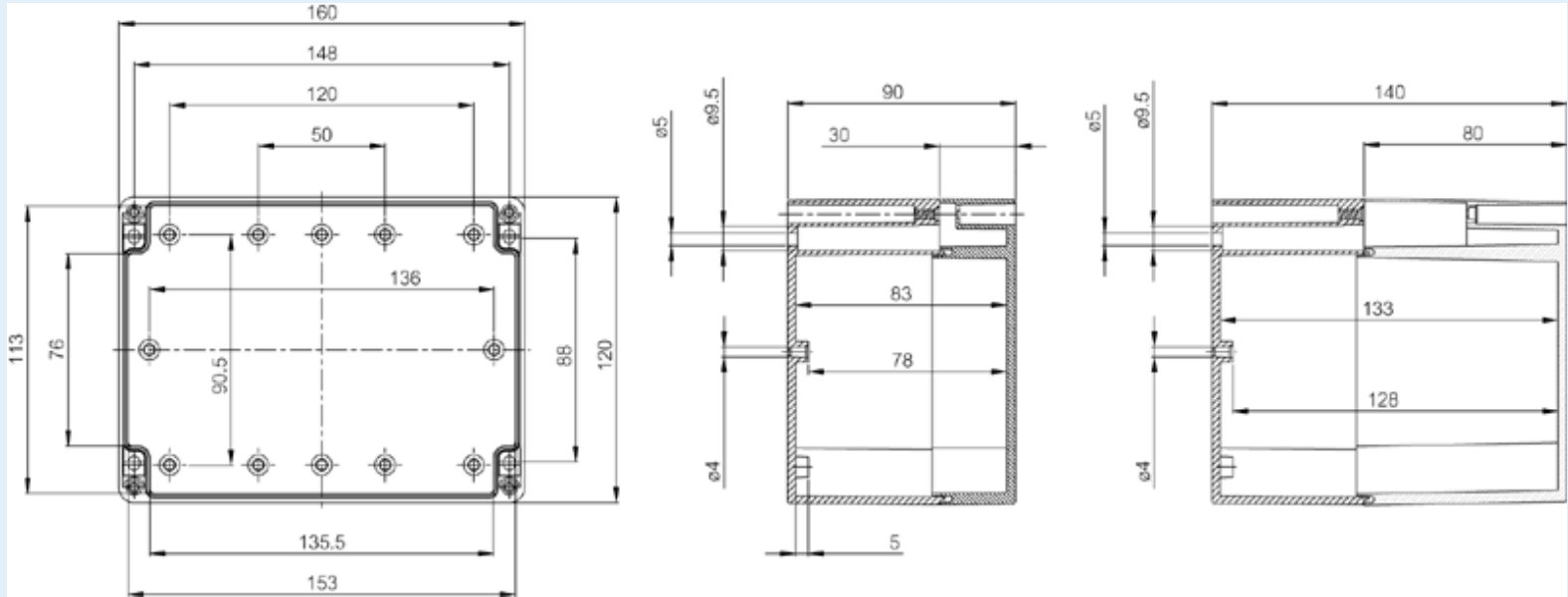

<b>Dimensions:</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm:	120	160	140
inch:	4.72	6.3	5.51

## **Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey

## **Accessories:**

MIV 10	DIN-35 Mounting rail. for enclosures: (100 x 35 x 1)
TF 28037	Mounting foot kit (4 pcs). for enclosures:
TRH 1216	DIN-15 Mounting rail. for enclosures: (146 x 35 x 1)
TRM 0816	DIN-15 Mounting rail. for enclosures: (146 x 15 x 1)

Cover colour: RAL 7035 -light grey

Gasket material: Polyurethane

TM 1216 Back Panel. for enclosures:  
(111 x 134 x 1)

TH A Gray plastic hinges (2 pcs)

#### Temperatures:

Temperature °C (short term):: -40 ... 120

Temperature °C (continuous): -40 ... 80

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

#### Rating:

Ingress protection (EN 60529): IP66; IP67;

Impact Resistance (EN 62262): IK07; IK08;

Electrical insulation: Totally insulated

Halogen free (DIN/VDE 0472, Part 815): 1

UV resistance: UL 508

Flammability Rating: UL 746C 5"

Glow Wire Test (IEC 695-2-1) °C: 960 °C

NEMA Class

#### Certificates:

SGSFimko\_EURONORD