

PC 122410



Sample image

Order symbol: PC 122410

Product nbr: 7032780

Description: Enclosure. PC


Remarks: Opaque cover

EAN: 6418074058430

El. number:

- Finland: 3435366
- Denmark: 8212002908
- Sweden: 2536140

Including: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

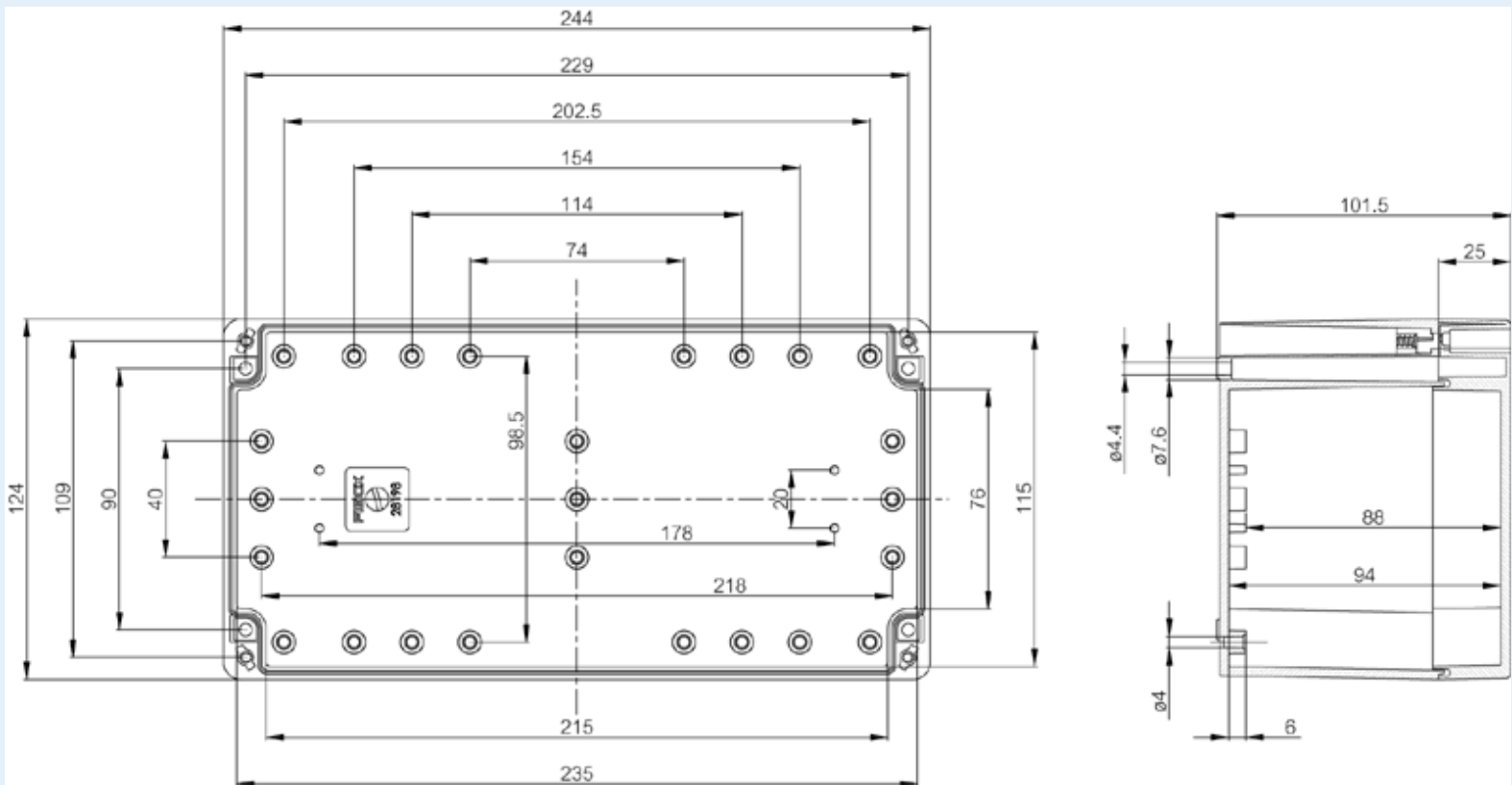

Dimensions:	Height	Width	Depth
mm:	124	244	102
inch:	4.88	9.61	4.02

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

TRH 1212	DIN-15 Mounting rail. for enclosures: (110 x 35 x 1)
TRH 24	DIN-15 Mounting rail. for enclosures: (226 x 35 x 1)
TRM 0812	DIN-15 Mounting rail. for enclosures: (106 x 15 x 1)
TF 28037	Mounting foot kit (4 pcs). for enclosures:
MIN 20	DIN-15 Mounting rail. for enclosures: (225 x 15 x 1)
TH A	Gray plastic hinges (2 pcs)
TM 1224	Back Panel. for enclosures:

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

SGSFimko_EURONORD