

# PC 153410



Sample image

**Order symbol:** PC 153410

**Product nbr:** 7032700

UL Code: 7042700

UL Name: UL PC 153410

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**EAN:** 6418074058447

**El. number:**

- Finland: 3435368
- Denmark: 8212004359
- Sweden: 2536141

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

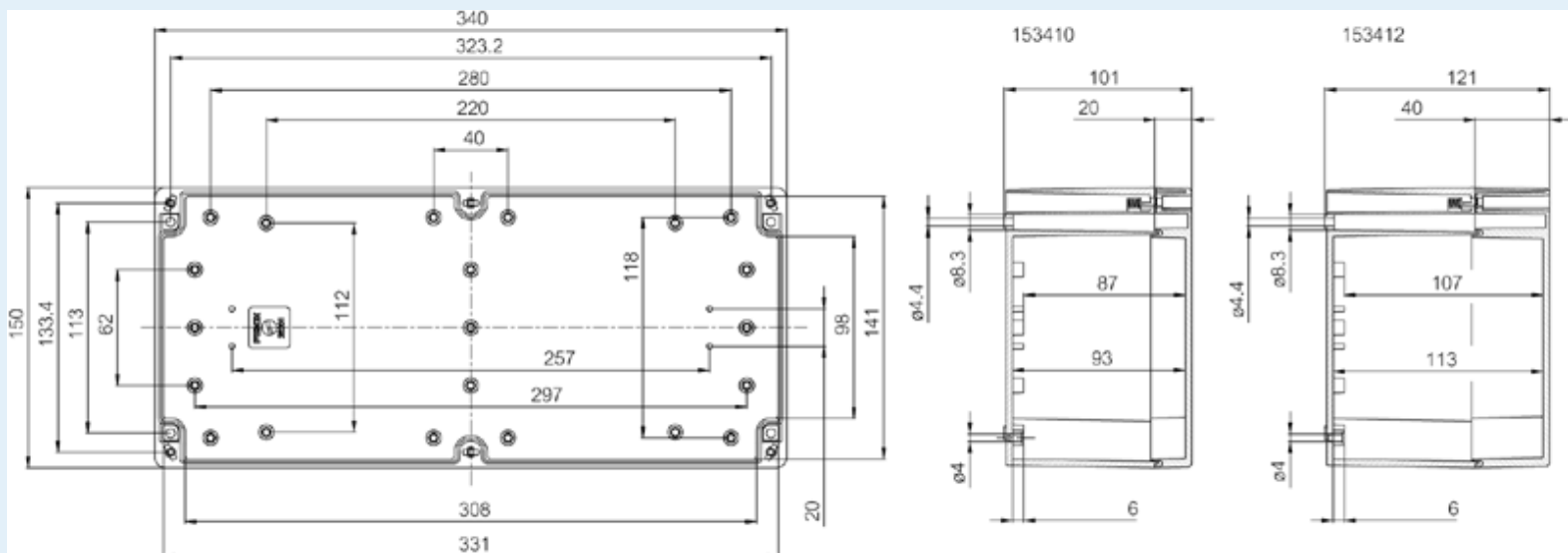

Dimensions:	Height	Width	Depth
mm:	150	340	100

**Accessories:**  
TRH 34 DIN-15 Mounting rail. for enclosures:

inch:	5.91	13.39	3.94
-------	------	-------	------

**Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

**Temperatures:**

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

(307 x 35 x 1)

TF 28037	Mounting foot kit (4 pcs). for enclosures:
TRH 15	DIN-15 Mounting rail. for enclosures: (122 x 35 x 1)
TM 1534	Back Panel. for enclosures: (303 x 136 x 1)
TH A	Gray plastic hinges (2 pcs)

**Rating:**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

**Certificates:**

SGSFimko\_EURONORD