

# PC 163610



Sample image

**Order symbol:** PC 163610

**Product nbr:** 7032750

UL Code: 7042750

UL Name: UL PC 163610

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**EAN:** 6418074058492

**El. number:**

- Finland: 3435378
- Denmark: 8212003169
- Sweden: 2536133

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

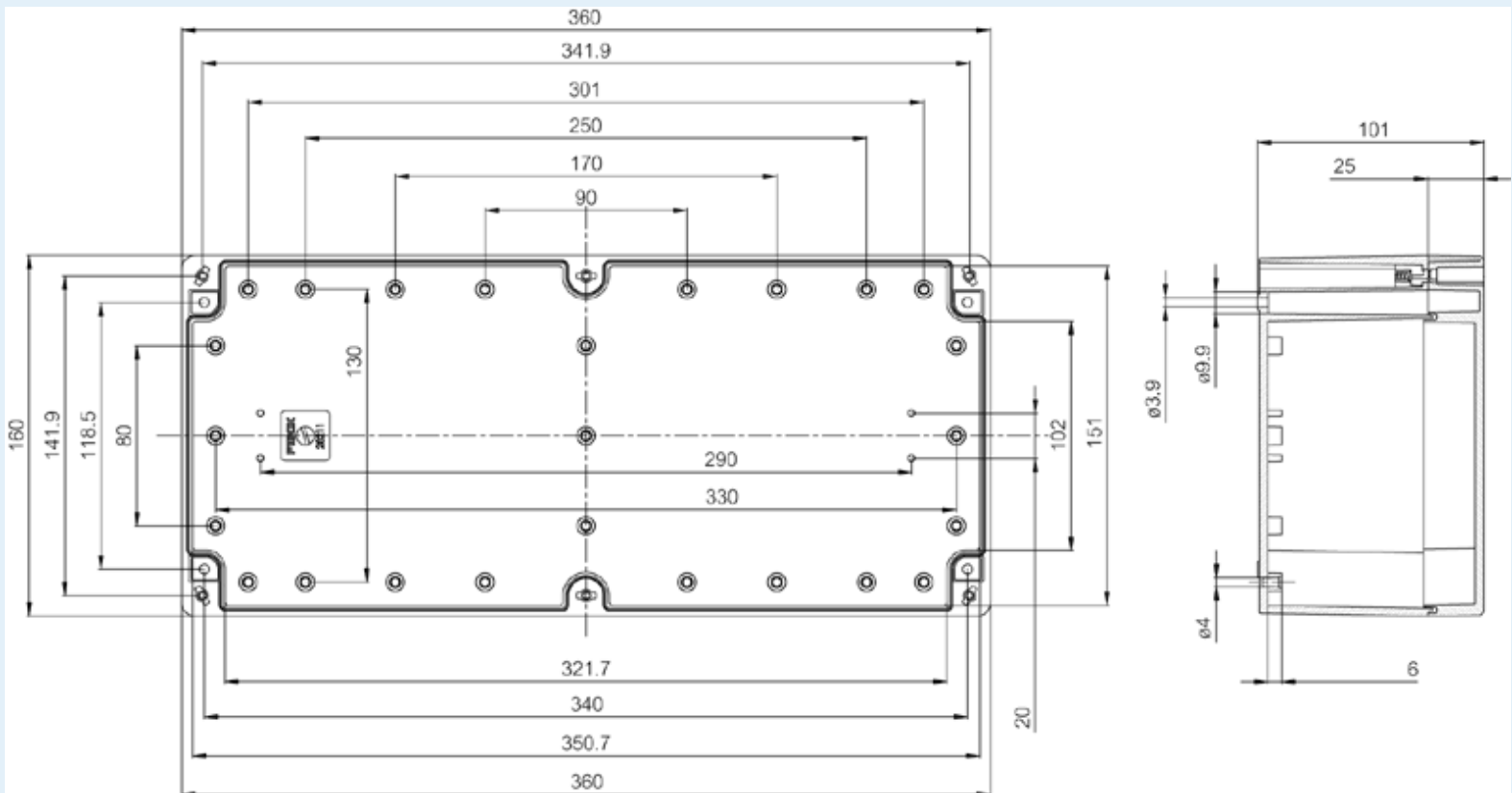

<b>Dimensions:</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm:	160	360	100
inch:	6.3	14.17	3.94

#### **Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### **Temperatures:**

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### **Accessories:**

TF 28037	Mounting foot kit (4 pcs). for enclosures:
ARM 0615	DIN-15 Mounting rail. for enclosures: (140 x 15 x 1)
TM 1636	Back Panel. for enclosures: (318 x 146 x 1)
DH-3	DIN-35 Mounting rail. for enclosures: (140 x 35 x 1)
TH A	Gray plastic hinges (2 pcs)
TRH 2036	DIN-15 Mounting rail. for enclosures: (35 x 340 x 1)

#### **Rating:**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### **Certificates:**

SGSFimko\_EURONORD