

MPMP ARCA 8060



Sample image

Order symbol: MPMP ARCA 8060

Product nbr: 8120928

Description: Mounting plate multiperforated (730x530x2 mm - \varnothing 3.6 mm)


Remarks: Galvanized steel. for size 800x600x300

EAN: 6418074089557

Including:

El. number:

- Finland:
- Denmark:
- Sweden:

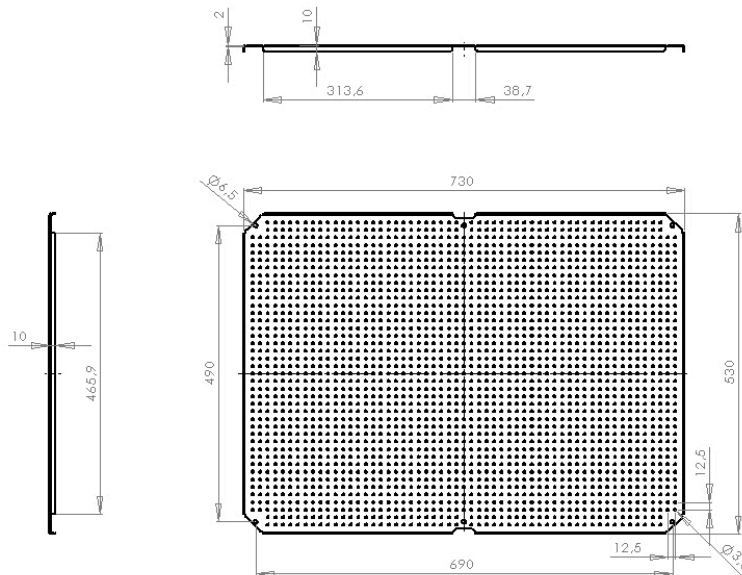

Dimensions:

	Height	Width	Depth
mm:	730	530	2
inch:	0	0	0.08

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation:

Not insulated

Halogen free (DIN/VDE 0472, Part 815):

0

UV resistance:

-

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

C

NEMA Class

Temperatures:

Temperature °C (short term)::

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Certificates: