

# Product data sheet

Specifications

SQUARE D

Green Premium™



Low voltage transformer, encapsulated dry type, 3 phase, 15kVA, 480V primary, 208Y/120V secondary, Type 3R

15T2F

Product availability : Stock - Normally stocked in distribution facility

Price\* : 6,734.00 USD

## Main

Product or Component Type	Dry Sealed Transformer
Primary to Secondary Voltage	480 V delta 208Y/120 V
Full Capacity Taps	2 5 % FCBN

## Complementary

Enclosure Code	14C
Phase	3 phase
Power Rating	15 kVA
Temperature rise	115 °C
Height	14.75 in (374.65 mm)
Width	19.1 in (485.14 mm)
Depth	12.25 in (311.15 mm)
Enclosure mounting	Wall mounted
Net Weight	300 lb(US) (136.08 kg) 300.01 lb(US) (136.08 kg)
Enclosure Material	Painted sheet steel

## Environment

Enclosure Type	NEMA 3R
Insulation temperature	356 °F (180 °C)
Product Certifications	UL Listed cULus CSA

## Ordering and shipping details

Category	16277-RESIN LVGP XFMR
Discount Schedule	PE2
GTIN	785901359500
Nbr. of units in pkg.	1

\* Price is “List Price” and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package weight(Lbs)	323.00 lb(US) (146.51 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	14.10 in (35.814 cm)
Package 1 width	15.30 in (38.862 cm)
Package 1 Length	19.10 in (48.514 cm)
Unit Type of Package 2	PAL
Number of Units in Package 2	6
Package 2 Weight	1938.00 lb(US) (879.061 kg)
Package 2 Height	40.00 in (101.6 cm)
Package 2 width	40.00 in (101.6 cm)
Package 2 Length	48.00 in (121.92 cm)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Phenyl glycidyl ether, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
PVC free	Yes

Contractual warranty


Warranty	18 months
----------	-----------

Dimensions

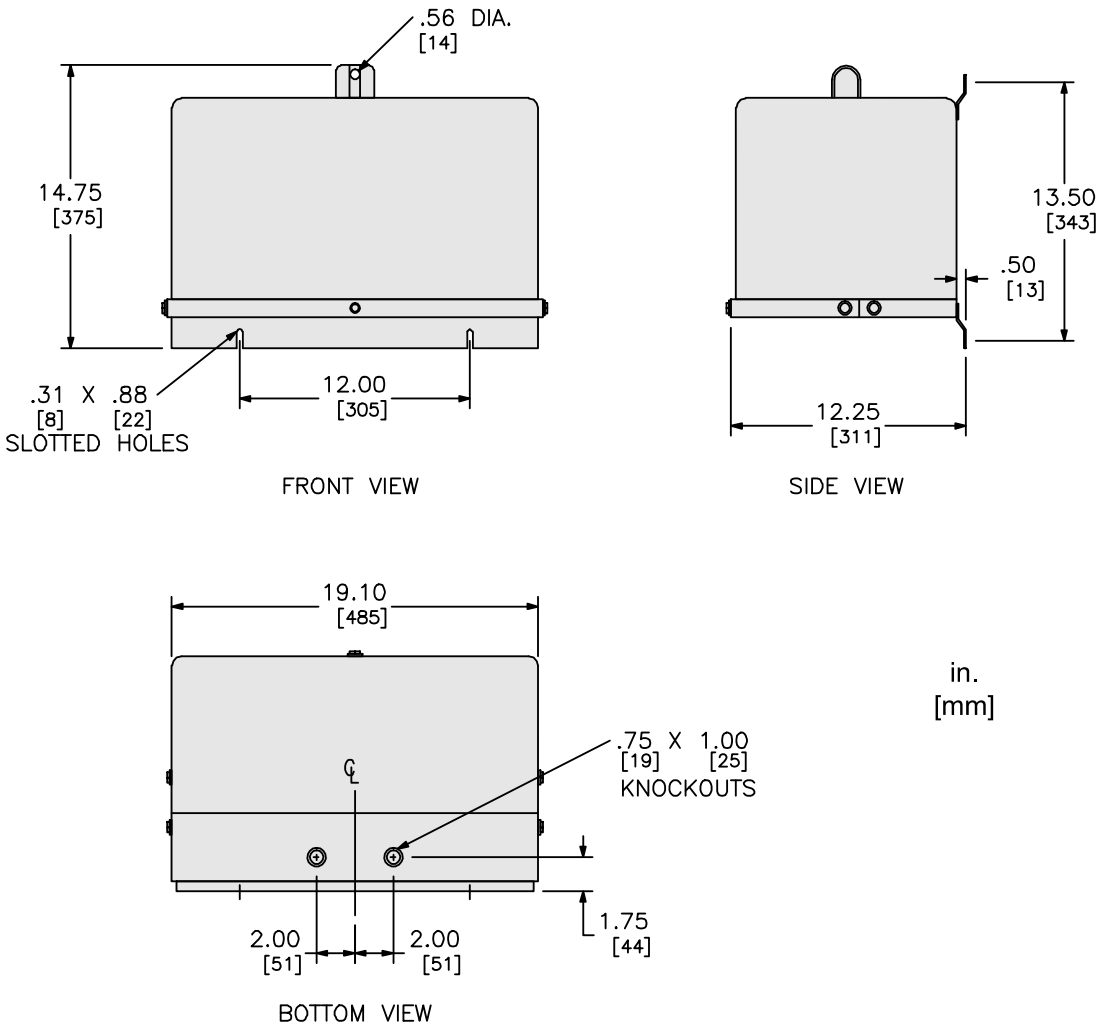

ALL DIMENSIONS ARE APPROXIMATE.  
ALSO REFER TO TECHNICAL DRAWINGS AND DOCUMENTATION.

Wiring Diagram

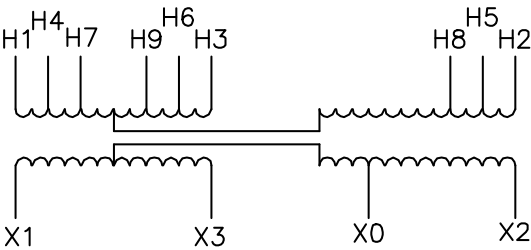

9T2F  
15T2F  
2 – 5% FCBN

480 DELTA – 208Y/120 CONNECT TO TAPS		
PRIMARY VOLTS	2–5% FCBN	2–2.5% FCAN 2–2.5% FCBN
504	–	H1, H2, H3
492	–	H4, H5, H6
480	H1, H2, H3	H7, H8, H9
468	–	H10, H11, H12
456	H4, H5, H6	H13, H14, H15
432	H7, H8, H9	–